


# nVent CADDY Cat 425 Adjustable Cable Support with C Purlin Clip

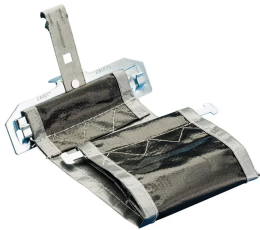

## CERTIFICATIONS



## FEATURES

Requires only a hammer to install

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Simple unlocking and locking of bar allows for additional cables to be added easily after installation

Adjustable strap allows for multiple support sizes to reduce inventory

Cost effective alternative to expensive cable tray

cULus® Listed and complies with NEC® and TIA requirements for structured cabling systems

Suitable for air handling spaces (plenum)

## SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Finish	Diameter (Ø)	Area	Cable Capacity, Cat 5e
CAT425VF14	181830	Steel, Polyethylene, Spring Steel	Electrogalvanized, nVent CADDY Armour	100 mm, 150 mm	518.92mm <sup>2</sup>	425

Table 2/2

Catalog Number	Article Number	Cable Capacity, Cat 6	Cable Capacity, Cat 6A	Flange Thickness (FT)	Static Load
CAT425VF14	181830	325	210	1.5 - 6 mm	450N

## DIAGRAMS

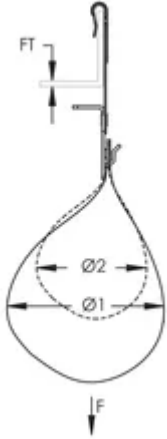

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

