

nVent CADDY Cat HP Extended Angle Bracket



CERTIFICATIONS



FEATURES

Allows for quick installation of J-Hooks to ceiling at set heights

Allows for field creation of custom J-Hook trees

Secure fit to J-Hooks means no shifting or movement of the J-Hook during cable installation

SPECIFICATIONS

Finish: Pregalvanized


Material: Steel

Table 1/1

Catalog Number	Hole Size (HS)	Length (L)	Width (W)	Depth (D)
CATHBA3	4.8 mm	318mm	44 mm	43mm
CATHBA	6.4 mm	318mm	44 mm	43mm
CATHBA6	9.5 mm	318mm	44 mm	43mm

Catalog Number	Hole Size (HS)	Length (L)	Width (W)	Depth (D)
CATHBA8	12.7 mm	318mm	44 mm	43mm

DIAGRAMS

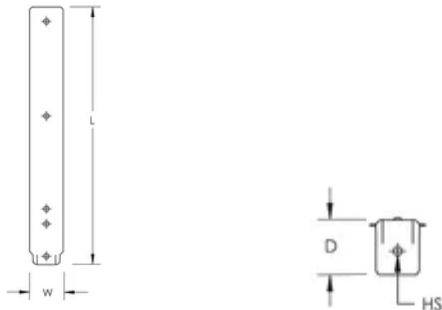

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

