


nVent CADDY Cat HP J-Hook Clip to Pedestal Clamp

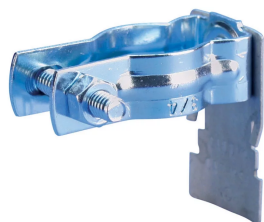

CERTIFICATIONS



FEATURES

Easy installation to pedestals used under raised floors

Requires no screws, rivets or special tools for assembly

J-Hooks feature bendable locking tabs that lock on to nVent CADDY Cat HP components to provide rigidity and stability

Link to J-Hooks in one of multiple color options to aid in pathway identification and organization

Customized J-Hook trees can be easily assembled with various J-Hook sizes, colors and configurations

nVent CADDY Cat HP components easily attach to any size nVent CADDY Cat HP J-Hook

SPECIFICATIONS

Finish: Electrogalvanized;nVent CADDY Armour

Material: Steel;Spring Steel

Table 1/1

Catalog Number	Article Number	Pedestal Size	Static Load
CATHPCD2.5B	181088	25.4 mm Square	70N

Catalog Number	Article Number	Pedestal Size	Static Load
CATHPCD0B	181085	19 mm Round	70N
CATHPCD1B	181086	19 mm Square, 22.2 - 28.5 mm Round	70N
CATHPCD2B	181087	22.2 mm Square	70N

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

