

# VF-Ti/T Rod to C-Purlin Clip



## CERTIFICATIONS



## FEATURES

Hammer-on or install from the floor with the VAFT tool

Provides an attachment for nVent CADDY Speed Link assemblies, wire, S-hooks, or chain from purlin and bar joist

## SPECIFICATIONS


**Finish:** nVent CADDY Armour

**Material:** Spring Steel

Table 1/1

Catalog Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	Height (H)	Static Load
VF144TI	0.25 mm	Threaded	1.5 - 6 mm	132 mm	700N
VF146T	9.5 mm	Plain	1.5 - 6 mm	132 mm	700N
VF146TI	0.375 mm	Threaded	1.5 - 6 mm	132 mm	700N

DIAGRAMS

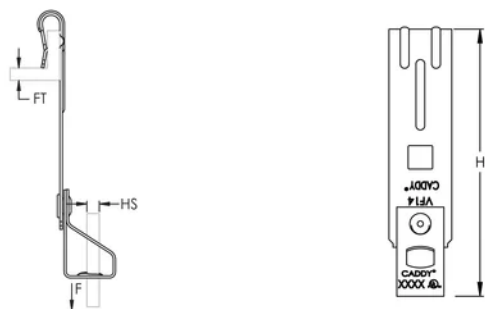

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

