


# Swan-Neck Link

## Data Solutions

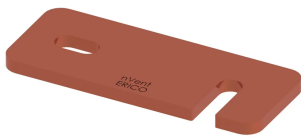

### FEATURES

Standalone link that joins two or more nVent ERICO electrical earth bars

High conductivity, hard drawn, electrolytic tough pitch copper per EN 13601

### SPECIFICATIONS

**Material:** Copper

Table 1/1


Catalog Number	Finish	Width (W)	Thickness (T)	Unit Weight
EEBDLC	Bare	50mm	6mm	0.3kg
EEBDLT	Tinned	50mm	6mm	0.3kg

### ADDITIONAL PRODUCT DETAILS

Tinned finish is 8 microns according to ASTM B545 Service Class "C" for corrosive environments.

## DIAGRAMS

---

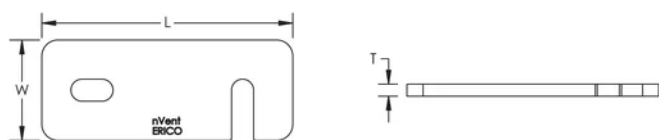

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**