


Cable/Point Pipe Support

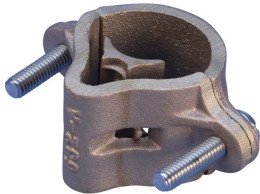

CERTIFICATIONS



FEATURES

Clamp for bonding horizontal or vertical pipes to the lightning protection system

May be used as a vertical support for air terminals

Listed to UL® 96

SPECIFICATIONS

Table 1/2


Catalog Number	Material	Finish	Diameter (Ø)	Outer Diameter (OD)	Depth (D)	Width (W)
LPA330	Aluminum	Bare	9.53 mm	35.6 - 44.45 mm	41.27mm	88.9 mm
LPA331	Aluminum	Bare	9.53 mm	44.5 - 63.5 mm	41.27mm	99 mm
LPC330	Brass	Bare	9.53 mm	35.6 - 44.45 mm	41.27mm	88.9 mm
LPC330L	Brass	Tinned	9.53 mm	35.6 - 44.45 mm	41.27mm	88.9 mm

CatalogNumber	Material	Finish	Diameter (Ø)	Outer Diameter (OD)	Depth (D)	Width (W)
LPC331L	Brass	Tinned	9.53 mm	44.5 - 63.5 mm	41.27mm	99 mm

Table 2/2

Catalog Number	Unit Weight	Certifications
LPA330	0.16 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPA331	0.16 kg	
LPC330	0.36 kg	
LPC330L	0.36 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC331L	0.38 kg	

DIAGRAMS

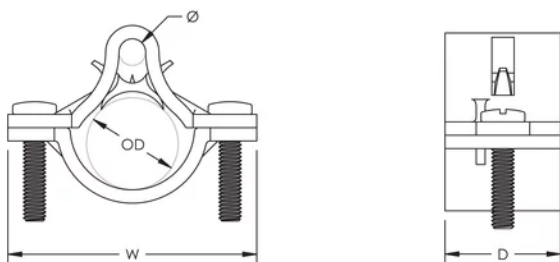

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE