

# Common Bonding Network Jumper



## FEATURES

Helps to achieve a secure electrical connection in telecommunications

Stranded wire allows for small radius bends

Tinned copper lug and hardware included

## SPECIFICATIONS

Table 1/3

Catalog Number	Material	Finish	Number of Wires	Insulation	Length (L)	Width (W)
CBNJ09P10	Steel, Copper	Electrogalvanized, Tinned	7	Green Insulated Conductor	32.3mm	12.2 mm

Table 2/3


Catalog Number	A	Thickness (T)	Hole Size (HS)	Slot Size (SS)	Angle (a)	Conductor Size
CBNJ09P10	14.4 mm	2 mm	6.9 mm	6.9 x 10.2 mm	45 °	#6 Stranded

Table 3/3

Catalog Number	Cable Length
CBNJ09P10	2.74m

## DIAGRAMS

---

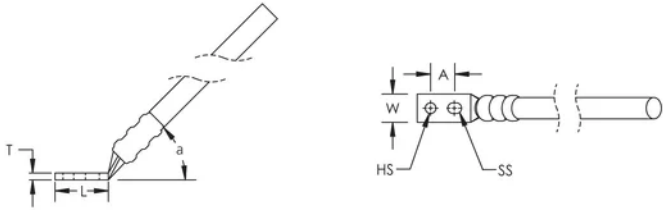

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**