


Rack Angles 24-inch

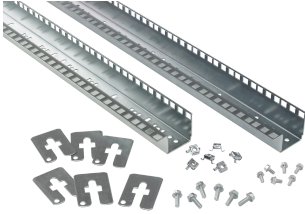

24-in. Rack Angles are available in both square-hole and tapped-hole designs. Tapped Rack Angles have 10-32 tapped holes. Square-Hole Rack Angles are designed to accept metric or English cage nuts. 24-in. Rack Angles fit directly into 700-mm wide frames or 800-mm wide frames using frame reducing brackets.

FEATURES

Furnished in pairs

Tapped-Hole Rack Angles are constructed from 12 gauge conductive steel, while Square-Hole Rack Angles are 14 gauge conductive steel

Tapped-Hole Rack Angles have 10-32 threaded holes; Square-Hole Rack Angles are designed to accept metric or English cage nuts.

Rack Angles fit directly into 700-mm wide frames, or 800-mm wide frames using frame reducing brackets (sold separately)

SPECIFICATIONS

Finish: Plated

Table 1/1						
Catalog Number	Article Number	Material	Rack Units	Hole Type	Thickness	Quick Ship
PRA2416TH	65210	Mild Steel	33U	Square	1.9mm	No
PRA2420TH	65230	Mild Steel	42U	Square	1.9mm	No
PRA2422TH	65240	Mild Steel	47U	Square	1.9mm	No
PRA2414TH	65200	Mild Steel	29U	Square	1.9mm	No
PRA2422TP	65690	Mild Steel	47U	Tapped	2.66mm	No
PRA2416TP	65270	Mild Steel	33U	Tapped	2.66mm	No
PRA2420TP	65290	Mild Steel	42U	Tapped	2.66mm	No
PRA2418TP	65280	Mild Steel	38U	Tapped	2.66mm	No
PRA247TP	65250	Mild Steel	13U	Tapped	2.66mm	No

ADDITIONAL PRODUCT DETAILS

Vertical holes spaced in 1.75-in. (44.5-mm) increments.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE