


Plug-In Unit U-Profile Front Panel for XL Handle

Front panel for XL handle. Shieldable with textile gasket. with or without cutout for a microswitch.

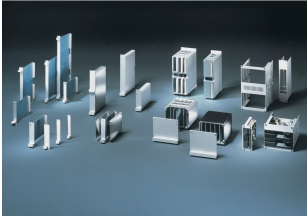

CERTIFICATIONS



FEATURES

Al, front anodized, sides and rear conductive

Suitable for sleeve and collar screw

U-front profile, shieldable, for inserter/extractor handle, type XL

SPECIFICATIONS

Material:	Aluminum
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel for Handle (PIU)
EMC Shielding:	No (Retrofittable)

Table 1/3

Catalog Number	Rack Width	Package Quantity	Handle Type	Mounting	Gasket Type	Front Finish
30849-153	4HP	1	XL	Screw-on Front	Textile EMC	Anodized

CatalogNumber	Rack Width	Package Quantity	Handle Type	Mounting	Gasket Type	Front Finish
30849-154	4HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-156	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-155	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-158	12HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-157	12HP	1	XL	Screw-on Front	Textile EMC	Anodized

Table 2/3

Catalog Number	Rear Finish	Treated Edges	Complies With	Depth (D)	Height (H)	Rack Height
30849-153	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-154	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-156	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-155	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-158	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-157	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U

Table 3/3

Catalog Number	Width (W)	Quick Ship
30849-153	20mm	No
30849-154	20mm	No
30849-156	40.3mm	No


Catalog Number	Width (W)	Quick Ship
30849-155	40.3mm	No
30849-158	60.6mm	No
30849-157	60.6mm	No

ADDITIONAL PRODUCT DETAILS

Delivery is exclusively in standard pack quantity, Please order EMC textile gasket and microswitch separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

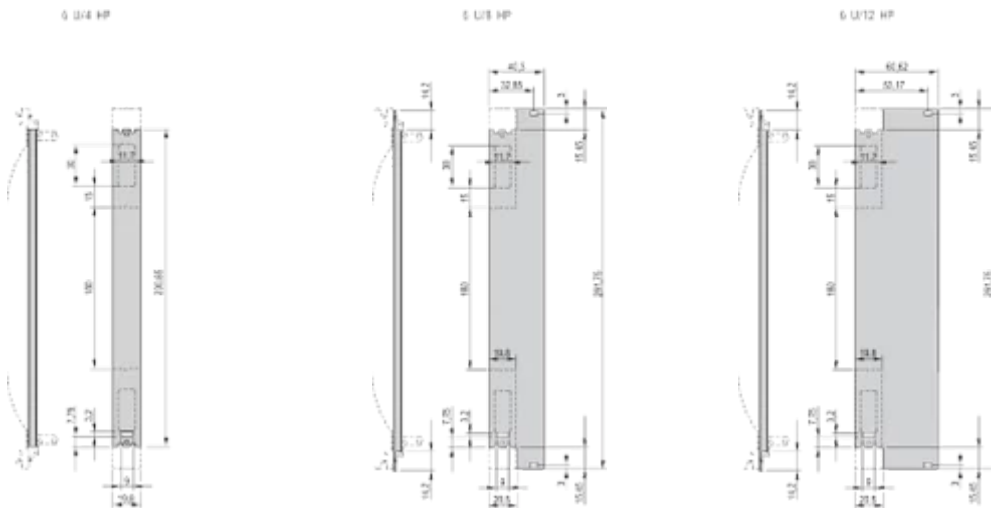

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE