


# Rear Panel for RatiopacPRO/PropacPRO, Perforated, Unshielded

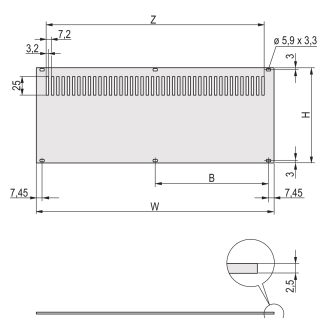

The perforated rear panel, Al, 2.5 mm is unshielded. The rear side is conductive.

## CERTIFICATIONS



## FEATURES

Rear panel, Al, 2.5 mm, front: anodized, rear: conductive; unshielded

Enables mounting on horizontal rails

For Mounting on Horizontal Rails

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized; Passivated
<b>Works With:</b>	Cases
<b>Product Family:</b>	RatiopacPRO; RatiopacPRO AIR
<b>Type:</b>	Rear Panel
<b>Product Type:</b>	Side Panel

Table 1/1

Catalog Number	Rack Height	Rack Width	Package Quantity	Height	Width	Quick Ship
----------------	-------------	------------	------------------	--------	-------	------------

30849-014	2U	42HP	1	67.9mm	213mm	No
30849-016	2U	84HP	1	67.9mm	426.4mm	No
30849-008	3U	28HP	1	112.35mm	141.9mm	No
30849-021	3U	42HP	1	112.35mm	213mm	No
30849-022	3U	63HP	1	112.35mm	319.7mm	No
30849-023	3U	84HP	1	112.35mm	426.4mm	No
30849-028	4U	42HP	1	156.8mm	213mm	No
30849-029	4U	63HP	1	156.8mm	319.7mm	No
30849-030	4U	84HP	1	156.8mm	426.4mm	No
30849-037	6U	84HP	1	245.7mm	426.4mm	No
30849-036	6U	63HP	1	245.7mm	319.7mm	No
30849-015	2U	63HP	1	67.9mm	319.7mm	No
30849-009	4U	28HP	1	156.8mm	141.9mm	No
30849-010	6U	28HP	1	245.7mm	141.9mm	No
30849-035	6U	42HP	1	245.7mm	213mm	No
30849-007	2U	28HP	1	67.9mm	141.9mm	No
30849-011	5U	28HP	1	220mm	215mm	No
30849-171	5U	42HP	1	220mm	215mm	No
30849-172	5U	63HP	1	220mm	215mm	No

30849-173		84HP	1	220mm	215mm	No
-----------	--	------	---	-------	-------	----

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**