


Varistar Shelf, Stationary, 75 kg

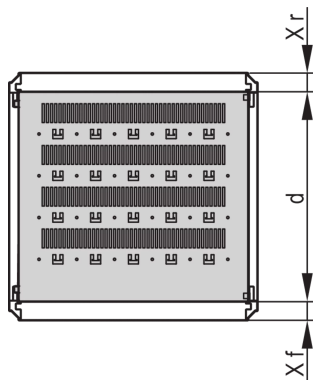

Varistar stationary shelf, either full length or shortened.

CERTIFICATIONS



FEATURES

1 U incl. GND/grounding

Mounts direct onto the Varistar rack

St, 1.5 mm

Static load-carrying capacity 75 kg

SPECIFICATIONS

Product Type: Shelf

Material: Steel

Table 1/2

Catalog Number	Width	Depth	Package Quantity	Color	Color Code	Finish
21130-322	544mm	479mm	1	Black Grey	RAL 7021	Powder Coated

CatalogNumber	Width	Depth	Package Quantity	Color	Color Code	Finish
21130-323	544mm	497mm	1	Black Grey	RAL 7021	Powder Coated
21130-324	544mm	597mm	1	Black Grey	RAL 7021	Powder Coated
21130-325	544mm	697mm	1	Black Grey	RAL 7021	Powder Coated
21130-326	544mm	797mm	1	Black Grey	RAL 7021	Powder Coated
21130-327	544mm	897mm	1	Black Grey	RAL 7021	Powder Coated
21130-332	744mm	479mm	1	Black Grey	RAL 7021	Powder Coated
21130-333	744mm	479mm	1	Black Grey	RAL 7021	Powder Coated
21130-334	744mm	597mm	1	Black Grey	RAL 7021	Powder Coated
21130-335	744mm	697mm	1	Black Grey	RAL 7021	Powder Coated
21130-336	744mm	797mm	1	Black Grey	RAL 7021	Powder Coated
21130-337	744mm	897mm	1	Black Grey	RAL 7021	Powder Coated
21130-550	544mm	997mm	1	Black Grey	RAL 7021	Powder Coated
21130-551	544mm	1097mm	1	Black Grey	RAL 7021	Powder Coated
21130-552	744mm	997mm	1	Black Grey	RAL 7021	Powder Coated
21130-553	744mm	1097mm	1	Black Grey	RAL 7021	Powder Coated
22130-322	544mm	497mm	1	Light Grey	RAL 7035	Powder Coated
22130-323	544mm	497mm	1	Light Grey	RAL 7035	Powder Coated
22130-324	544mm	697mm	1	Light Grey	RAL 7035	Powder Coated

CatalogNumber	Width	Depth	Package Quantity	Color	Color Code	Finish
22130-325	544mm	697mm	1	Light Grey	RAL 7035	Powder Coated
22130-326	544mm	797mm	1	Light Grey	RAL 7035	Powder Coated
22130-327	544mm	897mm	1	Light Grey	RAL 7035	Powder Coated
22130-332	744mm	497mm	1	Light Grey	RAL 7035	Powder Coated
22130-333	744mm	497mm	1	Light Grey	RAL 7035	Powder Coated
22130-334	744mm	597mm	1	Light Grey	RAL 7035	Powder Coated
22130-335	744mm	697mm	1	Light Grey	RAL 7035	Powder Coated
22130-336	744mm	797mm	1	Light Grey	RAL 7035	Powder Coated
22130-337	744mm	897mm	1	Light Grey	RAL 7035	Powder Coated
22130-550	544mm	997mm	1	Light Grey	RAL 7035	Powder Coated
22130-551	544mm	1097mm	1	Light Grey	RAL 7035	Powder Coated
22130-552	744mm	997mm	1	Light Grey	RAL 7035	Powder Coated
22130-553	744mm	1097mm	1	Light Grey	RAL 7035	Powder Coated

Table 2/2

Catalog Number	Type	Quick Ship
21130-322	Recessed Depth	No
21130-323	Full Depth	No
21130-324	Recessed Depth	No
21130-325	Full Depth	No

Catalog Number	Type	Quick Ship
21130-326	Full Depth	No
21130-327	Full Depth	No
21130-332	Recessed Depth	No
21130-333	Full Depth	No
21130-334	Recessed Depth	No
21130-335	Full Depth	No
21130-336	Full Depth	No
21130-337	Full Depth	No
21130-550	Full Depth	No
21130-551	Full Depth	No
21130-552	Full Depth	No
21130-553	Full Depth	No
22130-322	Recessed Depth	No
22130-323	Full Depth	No
22130-324	Recessed Depth	No
22130-325	Full Depth	No
22130-326	Full Depth	No
22130-327	Full Depth	No

Catalog Number	Type	Quick Ship
22130-332	Recessed Depth	No
22130-333	Full Depth	No
22130-334	Recessed Depth	No
22130-335	Full Depth	No
22130-336	Full Depth	No
22130-337	Full Depth	No
22130-550	Full Depth	No
22130-551	Full Depth	No
22130-552	Full Depth	No
22130-553	Full Depth	No

ADDITIONAL PRODUCT DETAILS

For the assembly of the shortened shelves 2 additional depth members are necessary, please order separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE