

PDRG Perforated Asymmetric Profile



CERTIFICATIONS



FEATURES

Rapid assembly of all kinds of frameworks

High mechanical resistance

High corrosion resistance

Conforms to EN 60715 and 50035 and DIN 46277

RoHS compliant

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel


Table 1/2

Catalog Number	Article Number	Height (H)	Width (W)	Length (L)	Thickness (T)	A
PDRG-2M	558050	32 mm	15 mm	2000mm	1.5 mm	9 mm
PDRG-3M	558060	32 mm	15 mm	3000mm	1.5 mm	9 mm

Table 2/2

Catalog Number	Article Number	B	C	D	Unit Weight
PDRG-2M	558050	7 mm	18 mm	6.2 mm	1.3 kg
PDRG-3M	558060	7 mm	18 mm	6.2 mm	1.96 kg

DIAGRAMS

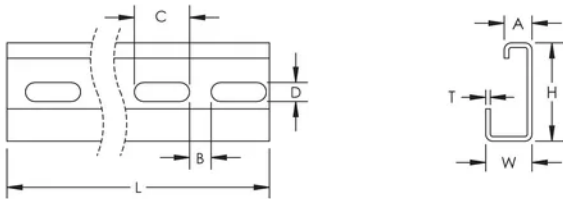

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE