


Busbar Adapter 63A With Cables, W060

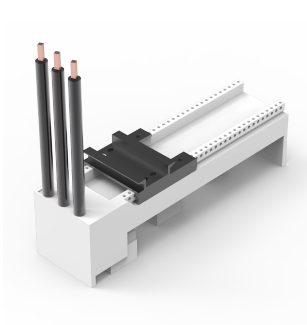

Busbar adapter with one mounting rail, pre-fitted with cables 10 mm².

INDUSTRY STANDARDS

UL

CSA

GL

FEATURES

Description: Busbar adapter 63 A. With one adjustable mounting rail. With cables 10 mm².

Rated voltage: 690 V

Rated current: 63 A

For busbars: 12, 15, 20, 25, 30 × 5, 10

Power dissipation at 80% load: 4.4 W

Poles: 3-pole

Pack quantity: 1 pc.

Approvals: CSA, UL, GL

SPECIFICATIONS

Table 1/1						
Catalog Number	Height	Width	Depth	Material	Finish	Color
32454	200mm	54mm	63mm	Plastic, Mild Steel	Plated	Black, Light Gray
32456	200mm	63mm	63mm	Plastic, Mild Steel	Plated	Black, Light Gray
32457	200mm	72mm	63mm	Plastic, Mild Steel	Plated	Black, Light Gray

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE