


# Closure Plate Lay-in Hinged-Cover

Lay-in Hinged-Cover Closure Plates are used for closing and sealing the end of a wireway section or run.

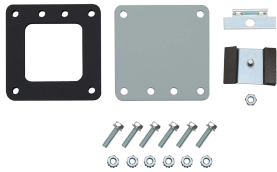

## FEATURES

---

Lay-in Hinged-Cover Closure Plates are used for closing and sealing the end of a wireway section or run

SPECIFICATIONS

- Color Code:** ANSI 61
- Finish:** Galvanized; Powder Coated
- Color:** Gray
- Material:** Mild Steel

| Table 1/1      |               |        |       |           |                    |                        |
|----------------|---------------|--------|-------|-----------|--------------------|------------------------|
| Catalog Number | Type          | Height | Width | Thickness | Sealing Plate Type | Sealing Plate Quantity |
| F22LP          | Closure Plate | 64mm   | 64mm  | 1.9mm     | 90°                | 1                      |
| F88LP          | Closure Plate | 203mm  | 203mm | 1.9mm     | 90°                | 1                      |
| F126LP         | Closure Plate | 305mm  | 152mm | 1.9mm     | 90°                | 1                      |
| F44LP          | Closure Plate | 102mm  | 102mm | 1.9mm     | 90°                | 1                      |
| F66LP          | Closure Plate | 152mm  | 152mm | 1.9mm     | 90°                | 1                      |

ADDITIONAL PRODUCT DETAILS

Each sealing plate also includes one gasket and one set of screws to join sections.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**