


# Interscale Mounting Plate for PCBs

Interscale mounting plate for the fixation of PCBs in small form factor desktop cases and 19" chassis.

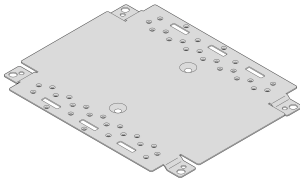

## FEATURES

Mounting plate (raised 4 mm) with integrated fan holder including fan kit for perforated case versions

Fans are simple to fit to the mounting plate using vibrationdamping fixing material

Does not fit for Interscale M for embedded NUC and 19"

## SPECIFICATIONS

|                        |                         |
|------------------------|-------------------------|
| <b>Finish:</b>         | Aluminum-Zinc Plated    |
| <b>Product Family:</b> | Interscale              |
| <b>Product Type:</b>   | Mounting Plate          |
| <b>Type:</b>           | Mounting Plate          |
| <b>Works With:</b>     | Small Form Factor Cases |
| <b>Material:</b>       | Steel                   |

Table 1/1

| Catalog Number | Width | Depth | Package Quantity | Height | Quick Ship |
|----------------|-------|-------|------------------|--------|------------|
| 24822-033      | 133mm | 133mm | 1                | 1mm    | No         |
| 24822-034      | 133mm | 177mm | 1                | 1mm    | No         |
| 24822-054      | 221mm | 177mm | 1                | 1mm    | No         |
| 24822-055      | 221mm | 221mm | 1                | 1mm    | No         |

| Catalog Number | Width | Depth | Package Quantity | Height | Quick Ship |
|----------------|-------|-------|------------------|--------|------------|
| 24822-075      | 310mm | 221mm | 1                | 1mm    | No         |
| 24822-095      | 399mm | 221mm | 1                | 1mm    | No         |
| 24822-005      | 444mm | 221mm | 1                | 1mm    | No         |
| 24822-097      | 399mm | 310mm | 1                | 1mm    | No         |
| 24822-007      | 444mm | 310mm | 1                | 1mm    | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**