


Plug-In Unit Kit With XL Handle, Shielded, Black, 6 U

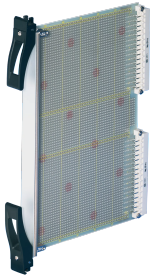

The XL handle is used for applications which requires high insertion / extraction forces such as VPX or VXS standards. Suitable for insertion and extractions forces up to 1500N (per pair).

CERTIFICATIONS



FEATURES

For applications which requires high insertion / extraction forces such as VPX or VXS standards

Additional board fixing options available

Handle requires additional die cast fixing block (combination with horizontal rail short / long lip)

U-shaped front panel for textile gasket

Suitable for insertion/extraction forces up to 1500 N (per pair)

IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10

SPECIFICATIONS

Rack Height:	6U
Material:	Aluminum
Finish:	Anodized; Passivated
Product Type:	Front Panel
Type:	Front Panel with Handle (PIU)
EMC Shielding:	Yes


Table 1/2						
Catalog Number	Rack Width	Package Quantity	Handle Type	Mounting	Gasket Type	Front Finish
20848-770	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
20848-771	12HP	1	XL	Screw-on Front	Textile EMC	Anodized
20848-769	4HP	1	XL	Screw-on Front	Textile EMC	Anodized

Table 2/2						
Catalog Number	Rear Finish	Treated Edges	Complies With	Height (H)	Width (W)	Quick Ship
20848-770	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEEE 1101.1	261.8mm	40.3mm	No
20848-771	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEEE 1101.1	261.8mm	60.6mm	No
20848-769	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEEE 1101.1	261.8mm	20mm	No

ADDITIONAL PRODUCT DETAILS

Kit with front panel for micro switch on request.

DIAGRAMS

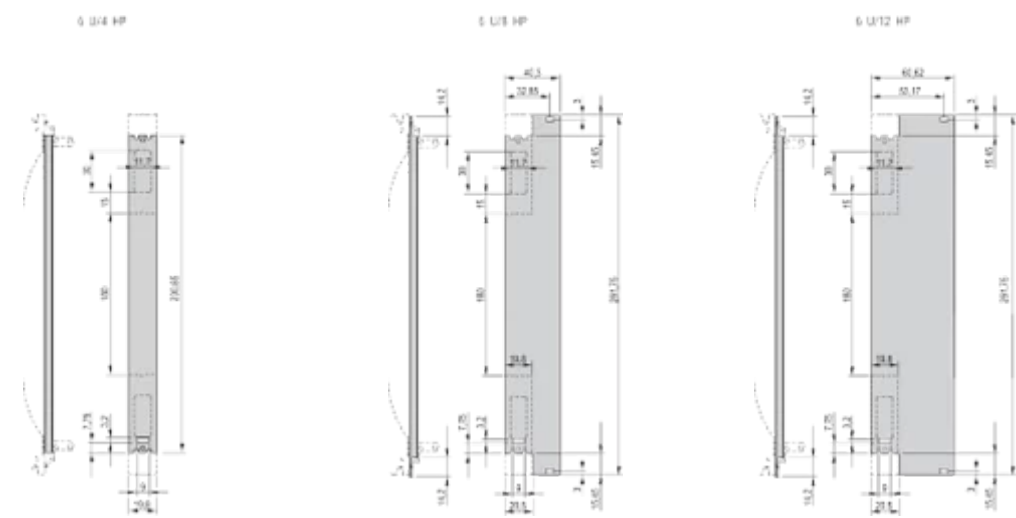

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE