

107 Wraparound Strap for CPVC Pipe



CERTIFICATIONS



FEATURES

Includes flared edges to protect piping

Rated for use with CPVC fire sprinkler pipe

Includes mounting screw

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	E-Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A
1070125EG	597818	3532439	32	42.2 mm	5.8 mm	41.3 mm
1070100EG	597817	3532438	25	33.7 mm	5.8 mm	36.5 mm
1070200EG	597821	3532442	50	60.3 mm	5.8 mm	47.6 mm

CatalogNumber	Article Number	E-Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	A
1070150EG	597819	3532441	40	48.3 mm	5.8 mm	44.5 mm
1070075EG	597816		20	26.9 mm	5.8 mm	31.8 mm

Table 2/2

Catalog Number	Article Number	E-Number	B	C	Hanger Spacing
1070125EG	597818	3532439	77.8 mm	30.2 mm	1.95 m Max
1070100EG	597817	3532438	68.3 mm	30.2 mm	1.8 m Max
1070200EG	597821	3532442	93.7 mm	30.2 mm	2.4 m Max
1070150EG	597819	3532441	84.1 mm	30.2 mm	2.1 m Max
1070075EG	597816		60.3 mm	30.2 mm	1.65 m Max

DIAGRAMS

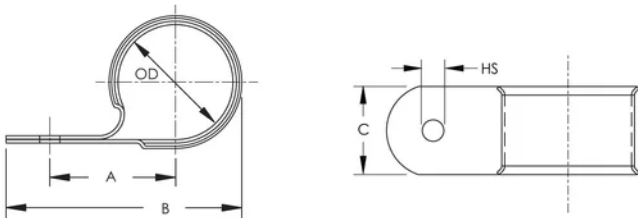

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

