

2-2 Hole Corner Gusset



FEATURES

Used to create metal frames with nVent CADDY Eristrut channels

SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	E-Number	Material	Finish	Orientation	Hole Size (HS)
ZWA207L	387675	3535059	Steel	Hot-Dip Galvanized	Left Hand	14 mm
ZWA207	387670	1319843	Steel	Hot-Dip Galvanized	Right Hand	14 mm
ZW207	313400	1319733	Steel	Hot-Dip Galvanized	Right Hand	14 mm
ZWA207EG	387671			Electrogalvanized	Right Hand	14 mm

Table 2/3


Catalog Number	Article Number	E-Number	Thickness (T)	A	B	Screw Included
ZWA207L	387675	3535059	6 mm	106 mm	89 mm	No
ZWA207	387670	1319843	6 mm	106 mm	89 mm	No

CatalogNumber	Article Number	E-Number	Thickness (T)	A	B	Screw Included
ZW207	313400	1319733	6 mm	106 mm	89 mm	Yes
ZWA207EG	387671			105 mm	90 mm	No

Table 3/3

Catalog Number	Article Number	E-Number	Screw Diameter (Sc)	Screw Length (L)
ZWA207L	387675	3535059		
ZWA207	387670	1319843		
ZW207	313400	1319733	10 mm	25mm
ZWA207EG	387671			

DIAGRAMS

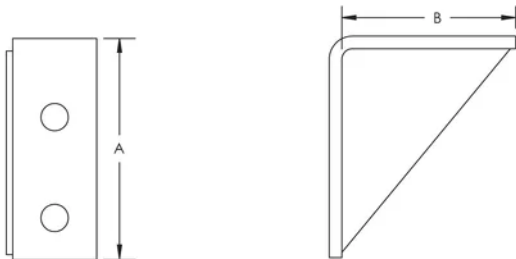

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

