


3000 Beam Clamp Kit

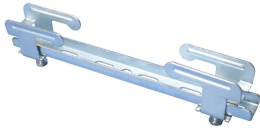

FEATURES

Medium duty system

Includes clamp and U channel

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/3

Catalog Number	Article Number	E-Number	Length (L)	Height (H)	Width (W)	Thickness (T)
3300EG	570410	1319890	300mm	15 mm	30 mm	2.5 mm
3400EG	570420	1319891	400mm	15 mm	30 mm	2.5 mm
3500EG	570430	1319892	500mm	15 mm	30 mm	2.5 mm
3600EG	570440	1319893	600mm	15 mm	30 mm	2.5 mm

Table 2/3

Catalog Number	Article Number	E-Number	Flange Thickness (FT)	Hole Size (HS)	Static Load 1 (F1)	Static Load 2 (F2)
----------------	----------------	----------	-----------------------	----------------	--------------------	--------------------

3300EG	570410	1319890	15 mm Max	13 mm	3700N	490N
3400EG	570420	1319891	15 mm Max	13 mm	3700N	490N
3500EG	570430	1319892	15 mm Max	13 mm	3700N	490N
3600EG	570440	1319893	15 mm Max	13 mm	3700N	490N

Table 3/3

Catalog Number	Article Number	E-Number	Static Load 3 (F3)
3300EG	570410	1319890	390N
3400EG	570420	1319891	390N
3500EG	570430	1319892	390N
3600EG	570440	1319893	390N

Screw Diameter (Sc): 8

X: 10.5 x 25 mm

D: 25 mm

Torque (TQ): 30 N·m


E: 31.5 mm

A: 40 mm

B: 100 mm

C: 150 mm

DIAGRAMS

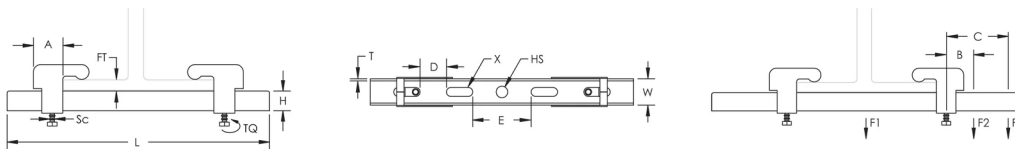

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

