

4G24H Twist Clip with 90° Plain Hole



CERTIFICATIONS



FEATURES

Provides an attachment for nVent CADDY Speed Link assemblies, wire, S-hooks, or chain from T-Grid

Fast, easy and secure twist-on installation

Designed to reduce scratching of T-grid

No tools required for installation

SPECIFICATIONS

Material: Spring Steel

Table 1/2


Catalog Number	Article Number	E-Number	Finish	Color	Hole Size (HS)	Flange Thickness (FT)
4G24H	170490	1341085	nVent CADDY Armour	Gray	5.8 mm	1.5 mm Max
4G24HWHSP25	172280	1340909	Painted	White	5.8 mm	1.5 mm Max

CatalogNumber	Article Number	E-Number	Finish	Color	Hole Size (HS)	Flange Thickness (FT)
4G24HWH	170500	1341088	Painted	White	5.8 mm	1.5 mm Max

Table 2/2

Catalog Number	Article Number	E-Number	T-Grid Size	Static Load
4G24H	170490	1341085	24mm	180N
4G24HWHSP25	172280	1340909	24mm	180N
4G24HWH	170500	1341088	24mm	180N

DIAGRAMS

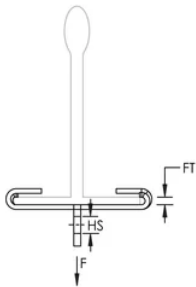

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

