

6000 Beam Clamp Kit



FEATURES

Back-to-back welded channels provide a smooth and easy adjustable fixing over the complete length of the channel

Pressure clamps grip the strut channel between two lips, protecting it from turning

Safe heavy duty fixing system for cable tray, duct or pipe

SPECIFICATIONS

Finish: Hot-Dip Galvanized

Material: Steel

Table 1/2

Catalog Number	Article Number	E-Number	Length (L)	Strut Type	Rod Size (RS)	Flange Thickness (FT)
6300CCHD	330000		300mm	CC (41 x 41 mm)	10	3 - 30 mm
6400AAHD	330110		400mm	AA (83 x 41 mm)	10	3 - 30 mm
6400CCHD	330010	1319754	400mm	CC (41 x 41 mm)	10	3 - 30 mm
6500CCHD	330020		500mm	CC (41 x 41 mm)	10	3 - 30 mm
6600AAHD	330130		600mm	AA (83 x 41 mm)	10	3 - 30 mm


CatalogNumber	Article Number	E-Number	Length (L)	Strut Type	Rod Size (RS)	Flange Thickness (FT)
6600CCHD	330030	1319755	600mm	CC (41 x 41 mm)	10	3 - 30 mm
6800AAHD	330140		800mm	AA (83 x 41 mm)	10	3 - 30 mm

Table 2/2

Catalog Number	Article Number	E-Number	A	B	Torque (TQ)
6300CCHD	330000		26 mm	13 mm	30 N·m
6400AAHD	330110		26 mm	13 mm	30 N·m
6400CCHD	330010	1319754	26 mm	13 mm	30 N·m
6500CCHD	330020		26 mm	13 mm	30 N·m
6600AAHD	330130		26 mm	13 mm	30 N·m
6600CCHD	330030	1319755	26 mm	13 mm	30 N·m
6800AAHD	330140		26 mm	13 mm	30 N·m

Strut Type	A	Static Load 1 F1	Static Load 2 F2
CC	200 mm	4000 N	1100 N
	300 mm	3000 N	750 N
	400 mm	2250 N	550 N
	500 mm	1800 N	450 N
	600 mm	1500 N	350 N
AA	200 mm	7000 N	3250 N
	300 mm	7000 N	2250 N
	400 mm	7000 N	1750 N
	500 mm	5500 N	1400 N
	600 mm	4500 N	1150 N

DIAGRAMS

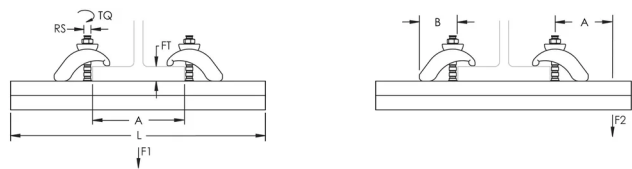

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

