

APX External Vertical Wall Bracket



FEATURES

Saddle support for C-Profiles and strut

Complete with fixings

SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	E-Number	Material	Finish	Channel Type	Strut Type
APXE01EG	584715	3435935	Steel	Electrogalvanized	E0L, E0, E1	
APXE23EG	584710	1319904	Steel	Electrogalvanized	E2L, E2, E3	
APXE4STRUTEG	584725	3532058	Steel	Electrogalvanized	E4	A (41 x 41 mm), C (21 x 41 mm)
APXSTRUTS6	584820	3435936	Stainless Steel 316 (EN 1.4401)			A (41 x 41 mm), C (21 x 41 mm)

Table 2/3


Catalog Number	Article Number	E-Number	Height (H)	Width (W)	Thickness (T)	A
APXE01EG	584715	3435935	114 mm	50 mm	5 mm	31 mm

CatalogNumber	Article Number	E-Number	Height (H)	Width (W)	Thickness (T)	A
APXE23EG	584710	1319904	114 mm	50 mm	5 mm	36 mm
APXE4STRUTE G	584725	3532058	144 mm	70 mm	5 mm	43 mm
APXSTRUTS6	584820	3435936	144 mm	70 mm	6 mm	43 mm

Table 3/3

Catalog Number	Article Number	E-Number	B	C
APXE01EG	584715	3435935	12 mm	19 mm
APXE23EG	584710	1319904	12 mm	19 mm
APXE4STRUTEG	584725	3532058	12 mm	19 mm
APXSTRUTS6	584820	3435936	12 mm	19 mm

DIAGRAMS

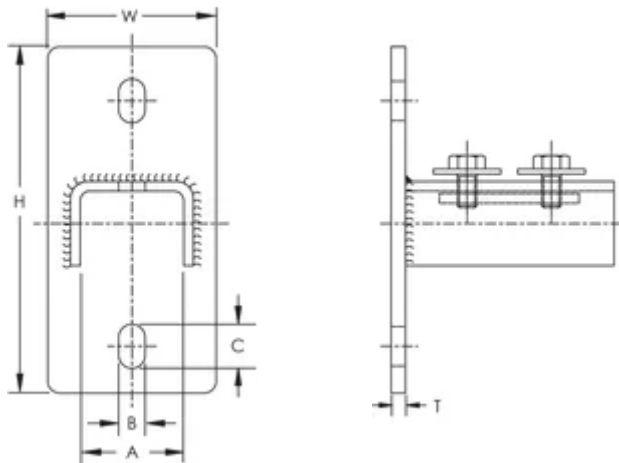

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

