


Beam Clamp with Swivel

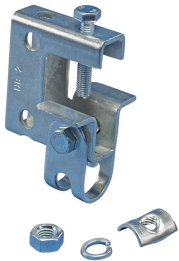

CERTIFICATIONS



FEATURES

Swivel beam clamp

Suitable for mounting onto sloped steel structures

Includes M10 nut and washer

SPECIFICATIONS

Material: Steel

Table 1/2

Catalog Number	Article Number	E-Number	Finish	Flange Thickness (FT)	Torque (TQ)	Angle 1 (a1)
HB2HD	336040	3535806	Hot-Dip Galvanized	24 mm Max	6 N·m	45 ° Min
HB2	336030	3535805	Electrogalvanized	24 mm Max	6 N·m	45 ° Min

Table 2/2


Catalog Number	Article Number	E-Number	Angle 2 (a2)
----------------	----------------	----------	--------------

HB2HD	336040	3535806	30 ° Max
HB2	336030	3535805	30 ° Max

ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

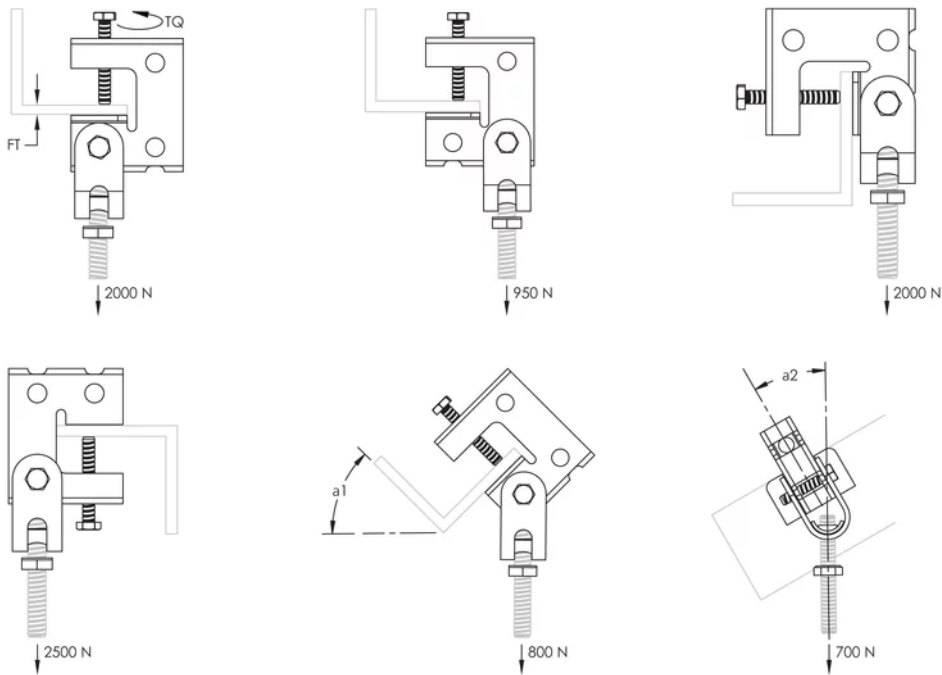

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

