

C-Channel U-Shaped Washer



FEATURES

U-shaped wrap around washer

For use with C-Profiles

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	E-Number	A	B	C	Thickness (T)
PLNE1208	588260		31 mm	30 mm	13.5 mm	2 mm
PLNE010	588250		28 mm	30 mm	15 mm	2 mm
PLUNI10	588290	1340673	35 mm	30 mm	10 mm	3 mm
PLNE3408	588280		39 mm	30 mm	17.5 mm	3 mm

Table 2/2

Catalog Number	Article Number	E-Number	Hole Size (HS)	Channel Type
PLNE1208	588260		8.5 mm	E0L, E0, E1

Catalog Number	Article Number	E-Number	Hole Size (HS)	Channel Type
PLNE010	588250		10.5 mm	E0, E0L
PLUN110	588290	1340673	10.5 mm	E1, E2, E2L
PLNE3408	588280		8.5 mm	E2, E3, E4

DIAGRAMS

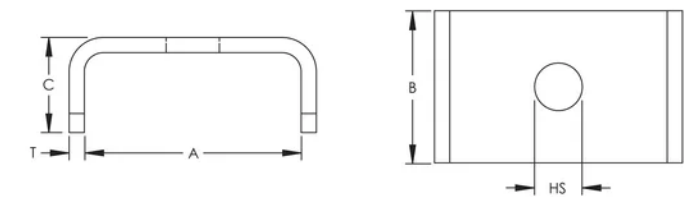

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

