

C-EU Single Cable to Flange Clamp



FEATURES

Supports single run of conduit

Attaches to beam flanges, angle iron, joists and other structural supports

SPECIFICATIONS

Finish: Hot-Dip Galvanized

Material: Steel

Table 1/1


Catalog Number	Article Number	E-Number	Outer Diameter (OD)	Flange Thickness (FT)	A	Torque (TQ)
C12EU	337300	1341255	8 - 12 mm	12 mm Max	41 mm Max	2 N·m
C16EU	337310	1341256	12 - 16 mm	12 mm Max	46 mm Max	2 N·m
C20EU	337320	1341257	16 - 20 mm	12 mm Max	50 mm Max	2 N·m
C24EU	337330	1341258	20 - 24 mm	12 mm Max	54 mm Max	2 N·m
C28EU	337340	1341259	24 - 28 mm	12 mm Max	58 mm Max	2 N·m
C32EU	337350	1341260	28 - 32 mm	12 mm Max	63 mm Max	2 N·m

CatalogNumber	Article Number	E-Number	Outer Diameter (OD)	Flange Thickness (FT)	A	Torque (TQ)
C36EU	337360	1341261	32 - 36 mm	12 mm Max	67 mm Max	2 N·m
C40EU	337370	1341262	36 - 40 mm	12 mm Max	71 mm Max	2 N·m
C44EU	337380	1341263	40 - 44 mm	12 mm Max	81 mm Max	4 N·m
C48EU	337390	1341264	44 - 48 mm	12 mm Max	85 mm Max	4 N·m
C52EU	337400	1341265	48 - 52 mm	12 mm Max	90 mm Max	4 N·m
C56EU	337410	1341266	52 - 56 mm	12 mm Max	94 mm Max	4 N·m
C60EU	337420	1341267	56 - 60 mm	12 mm Max	98 mm Max	4 N·m
C64EU	337430	1341268	60 - 64 mm	12 mm Max	102 mm Max	4 N·m

ADDITIONAL PRODUCT DETAILS

Screw is electrogalvanized on clamps that have an outer diameter of 40 mm or less.

DIAGRAMS

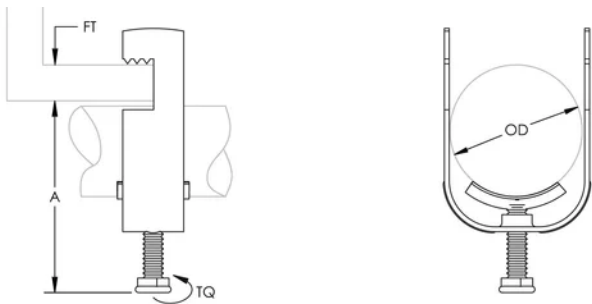

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

