

Cable Tie with Flange Clip



CERTIFICATIONS



FEATURES

Used to support cables from beam flanges

Requires only a hammer to install

Comes complete with zip-tie

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Flange Thickness (FT)	Cable Tie
2H4CTBB	170210	1319425	Spring Steel	nVent CADDY Armour	2 - 3 mm	Nylon Black
2H4CTBW	170170	1319421	Spring Steel	nVent CADDY Armour	2 - 3 mm	Nylon White
4H24CTBW	170180	1319422	Spring Steel	nVent CADDY Armour	3 - 8 mm	Nylon White
4H24CTBRS1	170280	1319429	Stainless Steel 301 (EN 1.4310)		3 - 8 mm	Stainless Steel 302 (EN 1.4324)


CatalogNumber	Article Number	E-Number	Material	Finish	Flange Thickness (FT)	Cable Tie
4H24CTBB	170220	1319426	Spring Steel	nVent CADDY Armour	3 - 8 mm	Nylon Black
4H58CTBW	170190	1319423	Spring Steel	nVent CADDY Armour	8 - 14 mm	Nylon White
4H58CTBB	170240	1341047	Spring Steel	nVent CADDY Armour	8 - 14 mm	Nylon Black
4H58CTBRS1	170300	1319431	Stainless Steel 301 (EN 1.4310)		8 - 14 mm	Stainless Steel 302 (EN 1.4324)
4H912CTBB	170260	1319428	Spring Steel	nVent CADDY Armour	14 - 20 mm	Nylon Black
4H912CTBW	170200	1319424	Spring Steel	nVent CADDY Armour	14 - 20 mm	Nylon White
4H912CTBRS1	170310	1319432	Stainless Steel 301 (EN 1.4310)		14 - 20 mm	Stainless Steel 302 (EN 1.4324)

Table 2/2

Catalog Number	Article Number	E-Number	Diameter (Ø)	Static Load	Certifications
2H4CTBB	170210	1319425	10 - 70 mm	150N	ITB
2H4CTBW	170170	1319421	10 - 70 mm	150N	ITB
4H24CTBW	170180	1319422	10 - 70 mm	150N	ITB
4H24CTBRS1	170280	1319429	25 - 51 mm	300N	
4H24CTBB	170220	1319426	10 - 70 mm	150N	ITB
4H58CTBW	170190	1319423	10 - 70 mm	150N	ITB
4H58CTBB	170240	1341047	10 - 70 mm	150N	ITB
4H58CTBRS1	170300	1319431	25 - 51 mm	300N	
4H912CTBB	170260	1319428	10 - 70 mm	150N	ITB

Catalog Number	Article Number	E-Number	Diameter (Ø)	Static Load	Certifications
4H912CTBW	170200	1319424	10 - 70 mm	150N	ITB
4H912CTBRS1	170310	1319432	25 - 51 mm	300N	

DIAGRAMS

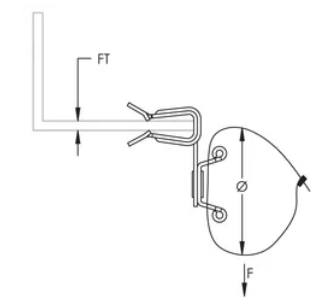

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

