

Cable Tie Holder with Flange Clip



CERTIFICATIONS



FEATURES

Used to support cables from beam flanges

Requires only a hammer to install

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Flange Thickness (FT)	A
2H4CT	178510	1341013	Spring Steel	nVent CADDY Armour	2 - 3 mm	9 mm
4H1318CT	178545		Spring Steel	nVent CADDY Armour	21 - 28 mm	9 mm
4H24CT	178520	1341014	Spring Steel	nVent CADDY Armour	3 - 8 mm	9 mm
4H24CTR5	191021	1319602	Spring Steel	nVent CADDY Armour	3 - 8 mm	9 mm


CatalogNumber	Article Number	E-Number	Material	Finish	Flange Thickness (FT)	A
4H24CTS1	160500		Stainless Steel 301 (EN 1.4310)		3 - 8 mm	9 mm
4H58CT	178530	1341015	Spring Steel	nVent CADDY Armour	8 - 14 mm	9 mm
4H58CTR5	191022	1319603	Spring Steel	nVent CADDY Armour	8 - 14 mm	9 mm
4H58CTS1	170430	1319433	Stainless Steel 301 (EN 1.4310)		8 - 14 mm	9 mm
4H58CTSP25	172360	1340913	Spring Steel	nVent CADDY Armour	8 - 14 mm	9 mm
4H912CT	178540	1341016	Spring Steel	nVent CADDY Armour	14 - 20 mm	9 mm
4H912CTR5	191023	1319604	Spring Steel	nVent CADDY Armour	14 - 20 mm	9 mm
4H912CTS1	170700	1319439	Stainless Steel 301 (EN 1.4310)		14 - 20 mm	9 mm
4H912CTSP25	172390	1340914	Spring Steel	nVent CADDY Armour	14 - 20 mm	9 mm

Table 2/2

Catalog Number	Article Number	E-Number	B	Static Load	Certifications
2H4CT	178510	1341013	2 mm	150N	ITB
4H1318CT	178545		2 mm	150N	
4H24CT	178520	1341014	2 mm	150N	ITB
4H24CTR5	191021	1319602	2 mm	150N	
4H24CTS1	160500		2 mm	150N	
4H58CT	178530	1341015	2 mm	150N	ITB
4H58CTR5	191022	1319603	2 mm	150N	

Catalog Number	Article Number	E-Number	B	Static Load	Certifications
4H58CTS1	170430	1319433	2 mm	150N	
4H58CTSP25	172360	1340913	2 mm	150N	
4H912CT	178540	1341016	2 mm	150N	ITB
4H912CTR5	191023	1319604	2 mm	150N	
4H912CTS1	170700	1319439	2 mm	150N	
4H912CTSP25	172390	1340914	2 mm	150N	

DIAGRAMS

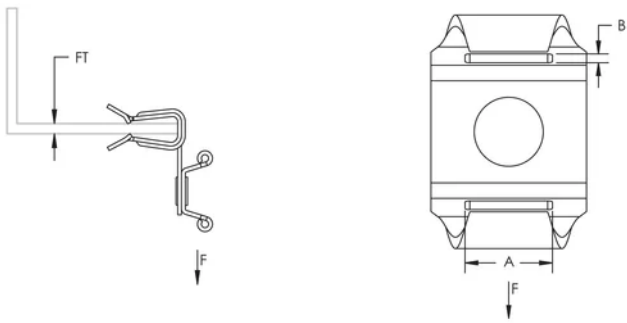

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

