

Cantilever Arm with E4 Channel



CERTIFICATIONS



FEATURES

Perforated, cold rolled

Slotted backplate

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel



Table 1/1

Catalog Number	Article Number	E-Number	Length (L)
CE420H0200EG	599935		200mm
CE420H0300EG	599950	3436018	300mm
CE420H0350EG	599960		350mm

Catalog Number	Article Number	E-Number	Length (L)
CE420H0450EG	599970	3436019	450mm
CE420H0550EG	599980	3436021	550mm
CE420H0650EG	599990	3436022	650mm
CE420H0800EG	599995		800mm

Thickness (T): 2 mm
E: 6 mm
X: 11 x 18 mm
Y: 14 x 27 mm
C: 15.5 mm
B: 38 mm
Width (W): 40 mm
A: 40 mm
D: 50 mm
Height (H): 120 mm

 DIAGRAMS

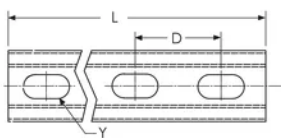

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

