

CHK Chain



CERTIFICATIONS



FEATURES

Versatile non-welded double loop chain

Conforms to DIN 5686

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	E-Number	Length (L)	A	B	D
CHK22K	385860	1319831	30m	28 mm	9 mm	2 mm
CHK25K	385870	1319832	30m	31 mm	10 mm	2.2 mm
CHK27K	385880	1319833	30m	35 mm	11 mm	2.5 mm

CatalogNumber	Article Number	E-Number	Length (L)	A	B	D
CHK30K	385890	1319834	30m	39 mm	12.5 mm	2.8 mm
CHK32K	385900	1319835	25m	41 mm	14 mm	3.1 mm

Table 2/2

Catalog Number	Article Number	E-Number	Static Load
CHK22K	385860	1319831	400N
CHK25K	385870	1319832	500N
CHK27K	385880	1319833	700N
CHK30K	385890	1319834	900N
CHK32K	385900	1319835	1200N

DIAGRAMS

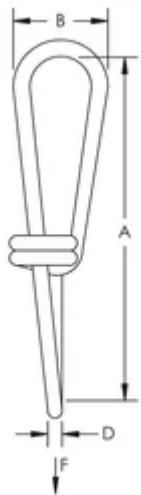

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

