

ECN Nut for C-Channel E0/E0L/E1



FEATURES

Channel nut for C-Profiles

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

Catalog Number	Article Number	E-Number	Channel Type	Rod Size (RS)	Thickness (T)	A
E01CNM6	315370	3435693	E0, E0L, E1	6	4 mm	23 mm
E01CNM8	315340	3435689	E0, E0L, E1	8	4 mm	23 mm
E01CNM10	315350	3435691	E0, E0L, E1	10	4 mm	23 mm

Table 2/2

Catalog Number	Article Number	E-Number	B
E01CNM6	315370	3435693	14 mm
E01CNM8	315340	3435689	14 mm


Catalog Number	Article Number	E-Number	B
E01CNM10	315350	3435691	14 mm

ADDITIONAL PRODUCT DETAILS

Sliding force F2 is limited to 600 N for all types of Nuts and T-Bolts for C-channel System.

Nuts and T-Bolts for C-channel System	
C-Channel Type	Pullout Force F1
E0	1000 N
E0L	1000 N
E1	1600 N

DIAGRAMS

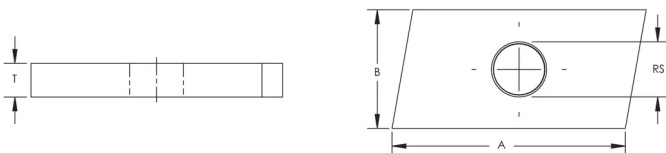

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

