

EM-M Conduit/Pipe to Flange Clip



CERTIFICATIONS



FEATURES

Supports conduit/pipe or cable from beam flanges

Snap close clip pivots a full 360°

Requires only a hammer to install

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)
8EM24S1	179780	1341370	Stainless Steel 301 (EN 1.4310)		18 - 22 mm	3 - 8 mm
16EM24	171740	1341358	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	3 - 8 mm
20EM24	171800	1341361	Spring Steel	nVent CADDY Armour	35 - 42 mm	3 - 8 mm
24EM24	171960	1341364	Spring Steel	nVent CADDY Armour	42 - 50 mm	3 - 8 mm

CatalogNumber	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)
32EM24	173600	1341367	Spring Steel	nVent CADDY Armour	50 - 60 mm	3 - 8 mm
812EM24	160120	1341355	Spring Steel	nVent CADDY Armour	18 - 30 mm	3 - 8 mm
12EM58S1	179820	1341374	Stainless Steel 301 (EN 1.4310)		22 - 30 mm	8 - 14 mm
16EM58	171490	1341359	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	8 - 14 mm
20EM58	171950	1341362	Spring Steel	nVent CADDY Armour	35 - 42 mm	8 - 14 mm
24EM58	171970	1341365	Spring Steel	nVent CADDY Armour	42 - 50 mm	8 - 14 mm
32EM58	173610	1341368	Spring Steel	nVent CADDY Armour	50 - 60 mm	8 - 14 mm
6EM58	171750	1341353	Spring Steel	nVent CADDY Armour	14 - 18 mm	8 - 14 mm
812EM58	160130	1341356	Spring Steel	nVent CADDY Armour	18 - 30 mm	8 - 14 mm
8EM58S1	179790	1341371	Stainless Steel 301 (EN 1.4310)		18 - 22 mm	8 - 14 mm
12EM912S1	179830	1341375	Stainless Steel 301 (EN 1.4310)		22 - 30 mm	14 - 20 mm
16EM912	173570	1341360	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	14 - 20 mm
20EM912	173580	1341363	Spring Steel	nVent CADDY Armour	35 - 42 mm	14 - 20 mm
24EM912	173590	1341366	Spring Steel	nVent CADDY Armour	42 - 50 mm	14 - 20 mm
32EM912	173620	1341369	Spring Steel	nVent CADDY Armour	50 - 60 mm	14 - 20 mm
812EM912	160140	1341357	Spring Steel	nVent CADDY Armour	18 - 30 mm	14 - 20 mm
8EM912S1	179800	1341372	Stainless Steel 301 (EN 1.4310)		18 - 22 mm	14 - 20 mm


CatalogNumber	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)
812EM1318	160075		Spring Steel	nVent CADDY Armour	18 - 30 mm	21 - 28 mm
16EM1318	173745		Spring Steel	nVent CADDY Armour	23.4 - 35 mm	21 - 28 mm

Table 2/2

Catalog Number	Article Number	E-Number	Static Load	Certifications
8EM24S1	179780	1341370	200N	
16EM24	171740	1341358	330N	ITB
20EM24	171800	1341361	330N	ITB
24EM24	171960	1341364	330N	ITB
32EM24	173600	1341367	330N	ITB
812EM24	160120	1341355	330N	ITB
12EM58S1	179820	1341374	200N	
16EM58	171490	1341359	330N	ITB
20EM58	171950	1341362	330N	ITB
24EM58	171970	1341365	330N	ITB
32EM58	173610	1341368	330N	ITB
6EM58	171750	1341353	330N	
812EM58	160130	1341356	330N	ITB
8EM58S1	179790	1341371	200N	
12EM912S1	179830	1341375	200N	

Catalog Number	Article Number	E-Number	Static Load	Certifications
16EM912	173570	1341360	330N	ITB
20EM912	173580	1341363	330N	ITB
24EM912	173590	1341366	330N	ITB
32EM912	173620	1341369	330N	ITB
812EM912	160140	1341357	330N	ITB
8EM912S1	179800	1341372	200N	
812EM1318	160075		330N	cUL, UL
16EM1318	173745		330N	cUL, UL

DIAGRAMS

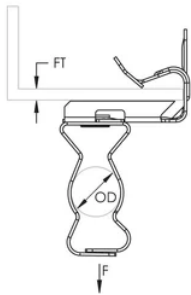

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

