

Four Hole Flat Tee Plate



FEATURES

Used to create metal frames with nVent CADDY Eristrut channels

SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	E-Number	Material	Finish	Hole Size (HS)	Thickness (T)
ZE108S6	388701		Stainless Steel 316 (EN 1.4401)		14 mm	6 mm
ZE108EG	378581			Electrogalvanized	14 mm	6 mm
ZE108	313080	1340575	Steel	Hot-Dip Galvanized	14 mm	6 mm
ZE108	387580	3535431	Steel	Hot-Dip Galvanized	14 mm	6 mm


Table 2/3

Catalog Number	Article Number	E-Number	A	B	Screw Included	Screw Diameter (Sc)
ZE108S6	388701		138 mm	90 mm	No	
ZE108EG	378581		135 mm	87.5 mm	No	

CatalogNumber	Article Number	E-Number	A	B	Screw Included	ScrewDiameter (Sc)
ZE108	313080	1340575	138 mm	90 mm	Yes	10 mm
ZE108	387580	3535431	138 mm	90 mm	No	

Table 3/3			
Catalog Number	Article Number	E-Number	Screw Length (L)
ZE108S6	388701		
ZE108EG	378581		
ZE108	313080	1340575	25mm
ZE108	387580	3535431	

DIAGRAMS

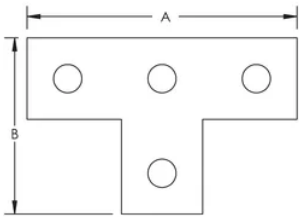

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

