

H-MSM Conduit/Pipe to Flange Clip, Side Mount



CERTIFICATIONS



FEATURES

Supports conduit/pipe or cable from beam flanges

Snap close clip pivots a full 360°

Requires only a hammer to install

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)
12M24SMS1	179690	1319529	Stainless Steel 301 (EN 1.4310)		22 - 30 mm	3 - 8 mm
16M24SM	173720	1319468	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	3 - 8 mm
20M24SM	171720	1319448	Spring Steel	nVent CADDY Armour	35 - 42 mm	3 - 8 mm
24M24SM	176690		Spring Steel	nVent CADDY Armour	42 - 50 mm	3 - 8 mm

CatalogNumber	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)
32M24SM	173830		Spring Steel	nVent CADDY Armour	50 - 60 mm	3 - 8 mm
6M24SM	173640	1341048	Spring Steel	nVent CADDY Armour	14 - 18 mm	3 - 8 mm
812M24SM	160050	1341051	Spring Steel	nVent CADDY Armour	18 - 30 mm	3 - 8 mm
8M24SMS1	179650		Stainless Steel 301 (EN 1.4310)		18 - 22 mm	3 - 8 mm
12M58SMS1	179700	1319530	Stainless Steel 301 (EN 1.4310)		22 - 30 mm	8 - 14 mm
16M58SM	173730	1319469	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	8 - 14 mm
20M58SM	173770	1319471	Spring Steel	nVent CADDY Armour	35 - 42 mm	8 - 14 mm
24M58SM	173800	1319473	Spring Steel	nVent CADDY Armour	42 - 50 mm	8 - 14 mm
32M58SM	173840	1319475	Spring Steel	nVent CADDY Armour	50 - 60 mm	8 - 14 mm
6M58SM	171980	1341049	Spring Steel	nVent CADDY Armour	14 - 18 mm	8 - 14 mm
812M58SM	160060	1341052	Spring Steel	nVent CADDY Armour	18 - 30 mm	8 - 14 mm
6M912SM	173650	1341050	Spring Steel	nVent CADDY Armour	14 - 18 mm	14 - 20 mm
812M1318SM	160145		Spring Steel	nVent CADDY Armour	18 - 30 mm	21 - 28 mm
812M912SM	160070	1341053	Spring Steel	nVent CADDY Armour	18 - 30 mm	14 - 20 mm
16M912SM	173740	1319470	Spring Steel	nVent CADDY Armour	23.4 - 35 mm	14 - 20 mm
20M912SM	173780	1319472	Spring Steel	nVent CADDY Armour	35 - 42 mm	14 - 20 mm
24M912SM	173810	1319474	Spring Steel	nVent CADDY Armour	42 - 50 mm	14 - 20 mm


CatalogNumber	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	Flange Thickness (FT)
8M912SMS1	179670		Stainless Steel 301 (EN 1.4310)		18 - 22 mm	14 - 20 mm

Table 2/2

Catalog Number	Article Number	E-Number	Static Load	Certifications
12M24SMS1	179690	1319529	90N	
16M24SM	173720	1319468	120N	UL, cUL
20M24SM	171720	1319448	120N	cUL, UL
24M24SM	176690		120N	cUL, UL
32M24SM	173830		120N	UL, cUL
6M24SM	173640	1341048	120N	UL, cUL
812M24SM	160050	1341051	120N	UL, ITB, cUL
8M24SMS1	179650		90N	
12M58SMS1	179700	1319530	90N	
16M58SM	173730	1319469	120N	UL, cUL
20M58SM	173770	1319471	120N	
24M58SM	173800	1319473	120N	cUL, UL
32M58SM	173840	1319475	120N	UL, cUL
6M58SM	171980	1341049	120N	UL, cUL
812M58SM	160060	1341052	120N	UL, cUL, ITB

Catalog Number	Article Number	E-Number	Static Load	Certifications
6M912SM	173650	1341050	120N	
812M1318SM	160145		120N	cUL, UL
812M912SM	160070	1341053	120N	ITB, UL, cUL
16M912SM	173740	1319470	120N	cUL, UL
20M912SM	173780	1319472	120N	
24M912SM	173810	1319474	120N	cUL, UL
8M912SMS1	179670		90N	

DIAGRAMS

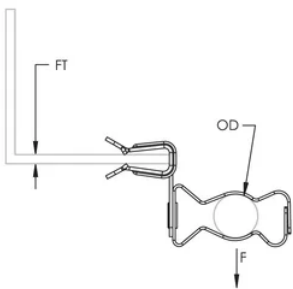

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

