

Hex Head Bolt

FEATURES

Fully threaded hexagon head bolt

SPECIFICATIONS


Complies With: DIN 933

Material: Steel

Table 1/1

Catalog Number	Article Number	E-Number	Finish	Screw Diameter (Sc)	Screw Length (L)
HSCRM825EG	593680		Electrogalvanized	8	25mm
HSCRM1025HD	593745	1342867	Hot-Dip Galvanized	10	25mm
HSCRM1030HD	593755	1342868	Hot-Dip Galvanized	10	30mm

DIAGRAMS

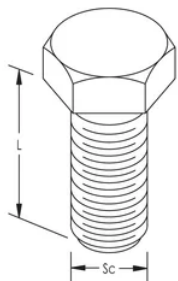

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

