


# nVent CADDY Macrofix Insulated M8

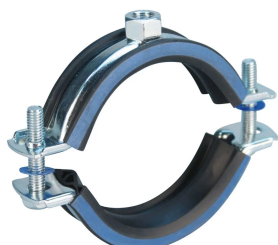

## CERTIFICATIONS



## FEATURES

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## SPECIFICATIONS

**Temperature:** -50 to 110 °C

**Finish:** Electrogalvanized

**Material:** EPDM-SBR Rubber;Steel

Table 1/2

Catalog Number	Article Number	E-Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
----------------	----------------	----------	---------------------	-------	---------------	-----------

MFE031	586204	3532844	25 - 31 mm	20	M8	20 mm
MFE037	586205	3532845	31 - 37 mm	25	M8	20 mm
MFE015	586201	3532841	11 - 15 mm	8	M8	20 mm
MFE019	586202	3532842	15 - 19 mm	10	M8	20 mm
MFE025	586203	3532843	19 - 25 mm	15	M8	20 mm
MFE044	586206	3532846	37 - 44 mm	32	M8	20 mm
MFE068	586209	3532849	58 - 68 mm	50	M8	20 mm
MFE058	586208	3532848	50 - 58 mm		M8	20 mm
MFE050	586207	3532847	44 - 50 mm	40	M8	20 mm

Table 2/2


Catalog Number	Article Number	E-Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
MFE031	586204	3532844	1 mm	6	22mm	1000N
MFE037	586205	3532845	1 mm	6	22mm	1000N
MFE015	586201	3532841	1 mm	6	17mm	1000N
MFE019	586202	3532842	1 mm	6	17mm	1000N
MFE025	586203	3532843	1 mm	6	22mm	1000N
MFE044	586206	3532846	1 mm	6	27mm	1000N
MFE068	586209	3532849	1.25 mm	6	32mm	1500N
MFE058	586208	3532848	1.25 mm	6	27mm	1500N

CatalogNumber	Article Number	E-Number	Thickness (T)	ScrewDiameter (Sc)	Screw Length (L)	Static Load
MFE050	586207	3532847	1.25 mm	6	27mm	1500N

### ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

### DIAGRAMS

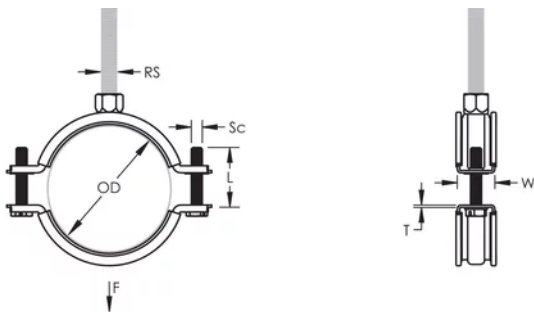

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

