

nVent CADDY Macrofix Non-Insulated M8/M10, Stainless Steel



CERTIFICATIONS



FEATURES

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

SPECIFICATIONS

Finish: Electropolished

Material: Stainless Steel 316L (EN 1.4404)

Table 1/2

Catalog Number	Article Number	E-Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
MFN019S6	586401	3533112	15 - 19 mm	10	M8, M10	20 mm


CatalogNumber	Article Number	E-Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
MFN023S6	586402	3533113	19 - 23 mm	15	M8, M10	20 mm
MFN029S6	586403	3533114	23 - 29 mm	20	M8, M10	20 mm
MFN035S6	586404	3533115	29 - 35 mm	25	M8, M10	20 mm
MFN041S6	586405	3533116	35 - 41 mm		M8, M10	20 mm
MFN048S6	586406	3533117	41 - 48 mm	32	M8, M10	20 mm
MFN054S6	586407	3533118	48 - 54 mm	40	M8, M10	20 mm
MFN062S6	586408	3533119	54 - 62 mm	50	M8, M10	20 mm
MFN072S6	586409	3533121	62 - 72 mm		M8, M10	20 mm
MFN083S6	586410	3533122	73 - 83 mm	65	M8, M10	23 mm
MFN093S6	586411	3533123	83 - 93 mm	80	M8, M10	23 mm
MFN103S6	586412	3533124	93 - 103 mm	90	M8, M10	23 mm
MFN113S6	586413	3533125	103 - 113 mm		M8, M10	23 mm
MFN123S6	586414	3533126	113 - 123 mm	100	M8, M10	23 mm
MFN133S6	586415	3533127	123 - 133 mm		M8, M10	23 mm
MFN143S6	586416	3533128	133 - 143 mm	125	M8, M10	23 mm
MFN165S6	586418	3533398	155 - 165 mm		M8, M10	25 mm
MFN175S6	586419	3533399	165 - 175 mm	150	M8, M10	25 mm
MFN220S6	586421	3533402	210 - 220 mm	200	M8, M10	27 mm

Table 2/2

Catalog Number	Article Number	E-Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
MFN019S6	586401	3533112	1 mm	6	17mm	900N
MFN023S6	586402	3533113	1 mm	6	17mm	900N
MFN029S6	586403	3533114	1 mm	6	17mm	900N
MFN035S6	586404	3533115	1 mm	6	17mm	900N
MFN041S6	586405	3533116	1 mm	6	22mm	900N
MFN048S6	586406	3533117	1 mm	6	22mm	900N
MFN054S6	586407	3533118	1.25 mm	6	22mm	1000N
MFN062S6	586408	3533119	1.25 mm	6	22mm	1000N
MFN072S6	586409	3533121	1.25 mm	6	22mm	1000N
MFN083S6	586410	3533122	1.5 mm	6	27mm	2000N
MFN093S6	586411	3533123	1.5 mm	6	27mm	2000N
MFN103S6	586412	3533124	1.75 mm	6	27mm	2500N
MFN113S6	586413	3533125	1.75 mm	6	27mm	2500N
MFN123S6	586414	3533126	1.75 mm	6	27mm	2500N
MFN133S6	586415	3533127	2 mm	6	27mm	3000N
MFN143S6	586416	3533128	2 mm	6	27mm	3000N
MFN165S6	586418	3533398	2 mm	6	27mm	3200N
MFN175S6	586419	3533399	2 mm	6	27mm	3200N

CatalogNumber	Article Number	E-Number	Thickness (T)	ScrewDiameter (Sc)	Screw Length (L)	Static Load
MFN220S6	586421	3533402	2.25 mm	6	32mm	3600N

DIAGRAMS

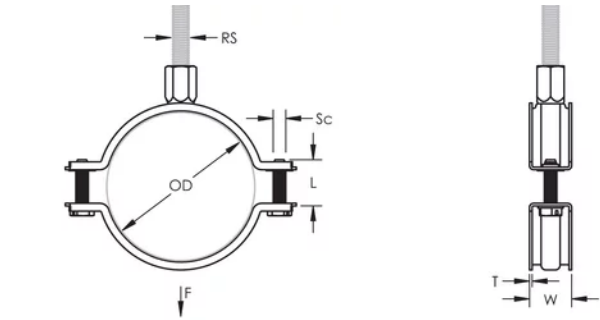

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

