

nVent CADDY Macrofix Plus NI EZ with Easy Closure



CERTIFICATIONS



FEATURES

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	E-Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Width (W)
MPZ040	595056	3532533	32	40.0 - 42.4 mm	M10	30 mm
MPZ025	595053	3532531	20	25.0 - 26.9 mm	M10	30 mm
MPZ032	595054	3532532	25	32.0 - 33.7 mm	M10	30 mm
MPZ020	595052	3532529	15	20.0 - 21.3 mm	M10	30 mm
MPZ050	595057	3532534	40	48.3 - 50 mm	M10	30 mm
MPZ075	595061	3532536	65	75.0 - 76.1 mm	M10	30 mm
MPZ063	595059	3532535	50	60.3 - 63 mm	M10	30 mm

Table 2/2

Catalog Number	Article Number	E-Number	Thickness (T)	Static Load	Certifications
MPZ040	595056	3532533	1.5 mm	1125N	AON Fire Protection, BB019, pipe hangers, FM Approved, Pipe Hanger Components
MPZ025	595053	3532531	1.5 mm	1125N	FM Approved, Pipe Hanger Components, AON Fire Protection, Macrofix Plus NI EZ
MPZ032	595054	3532532	1.5 mm	1125N	AON Fire Protection, BB019, pipe hangers, FM Approved, Pipe Hanger Components
MPZ020	595052	3532529	1.5 mm	1125N	AON Fire Protection, BB019, pipe hangers

Catalog Number	Article Number	E-Number	Thickness (T)	Static Load	Certifications
MPZ050	595057	3532534	2 mm	1725N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ075	595061	3532536	2 mm	1725N	
MPZ063	595059	3532535	2 mm	1725N	FM Approved, Pipe Hanger Components, AON Fire Protection, Macrofix Plus NI EZ

DIAGRAMS

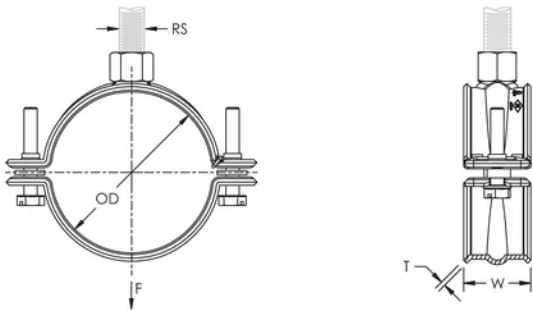

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

