


nVent CADDY Pyramid Equipment Support Post Base

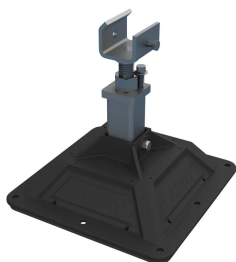

FEATURES

Ideal for use with strut channel type A and U-shaped brackets to create custom equipment supports

Height adjustable

Foam bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Provides superior load distribution, even with varying rooftop surfaces

Hot-dip galvanized and UV stabilized for long lasting performance

SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	E-Number	Material	Finish	Temperature	Static Load Safety Factor
PEB	360425	1319797	Steel, Polypropylene, Polyethylene	Hot-Dip Galvanized	-34 to 54.4 °C	3:1

Table 2/3

Catalog Number	Article Number	E-Number	Height (H)	Length (L)	Width (W)	A
PEB	360425	1319797	305 - 457 mm	314mm	314 mm	76 mm


Table 3/3

Catalog Number	Article Number	E-Number	Surface Area	Unit Weight	Static Load
PEB	360425	1319797	0.09m ²	4 kg	3340N

ADDITIONAL PRODUCT DETAILS

The end user must select and evaluate the strut framing to ensure the custom assembled equipment support can properly support the applied load.

DIAGRAMS

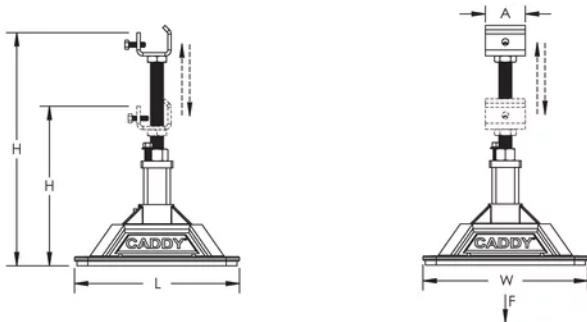

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

