

nVent CADDY Speed Link SLDM with Hook



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled hook end fitting

Ideal for supporting lighting, ductwork and other installation projects

Sleek, low-profile locking device reduces visual impact

Keyless locking device is adjustable even after installation

SPECIFICATIONS

Wire Rope Diameter:	1.5 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel

Table 1/2

Catalog Number	Article Number	E-Number	Wire Rope Length	A	B	C
SLDM615L2	196029	1319631	2m	58.4 mm	22.9 mm	6.4 mm

CatalogNumber	Article Number	E-Number	Wire Rope Length	A	B	C
SLDM615L1	196028	1319630	1m	58.4 mm	22.9 mm	6.4 mm

Table 2/2			
Catalog Number	Article Number	E-Number	Static Load
SLDM615L2	196029	1319631	195N
SLDM615L1	196028	1319630	195N

Rod Size (RS):

6

Length (L):

7mm


Width (W):

9.2 mm

Height (H):

24.5 mm

DIAGRAMS

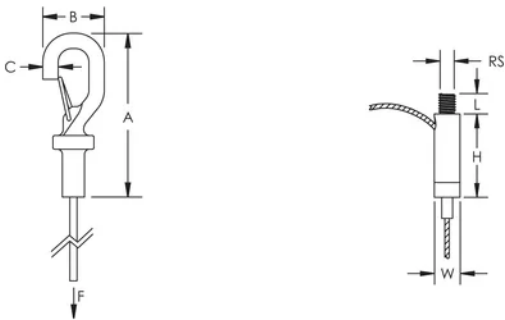

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

