

nVent CADDY Speed Link SLDM with Toggle



FEATURES

Complete system includes wire, locking device and pre-assembled toggle end fitting

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Sleek, low-profile locking device reduces visual impact

Keyless locking device is adjustable even after installation

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	E-Number	Material	Finish	Wire Rope Diameter	Wire Rope Length
SLDM615L2T	196044	1319635	Steel	Electrogalvanized	1.5 mm	2m

Table 2/2

Catalog Number	Article Number	E-Number	A	B	Static Load
SLDM615L2T	196044	1319635	39 mm	5 mm	195N

Rod Size (RS): 6
Length (L): 7mm
Width (W): 9.2 mm
Height (H): 24.5 mm

DIAGRAMS

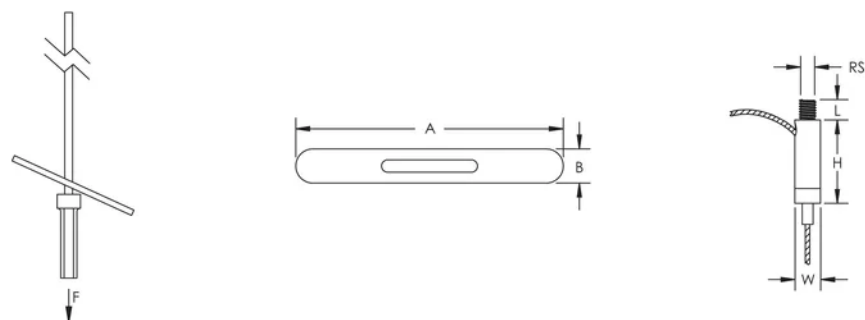

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

