

nVent CADDY Speed Link SLK with Angle Bracket



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled angle bracket end fitting

Ideal for attaching to concrete, steel or wood surfaces

Simple alternative to jack chain and additional hardware

SPECIFICATIONS

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Zinc Alloy;Polypropylene
Complies With:	SMACNA HVAC-DCS

Table 1/3

Catalog Number	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)
SLK15L1AB	196500		1.5 mm	1m	22.6 mm	7.1 mm

CatalogNumber	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)
SLK15L2AB	196501	1319638	1.5 mm	2m	22.6 mm	7.1 mm
SLK15L3AB	196502		1.5 mm	3m	22.6 mm	7.1 mm
SLK15L5AB	196503		1.5 mm	5m	22.6 mm	7.1 mm
SLK2L2AB	196529		2 mm	2m	22.6 mm	7.1 mm
SLK2L3AB	196530		2 mm	3m	22.6 mm	7.1 mm
SLK2L5AB	196531		2 mm	5m	22.6 mm	7.1 mm
SLK3L10AB	196716		3 mm	10m	22.6 mm	7.1 mm
SLK3L2AB	196713		3 mm	2m	22.6 mm	7.1 mm
SLK3L5AB	196715		3 mm	5m	22.6 mm	7.1 mm

Table 2/3


Catalog Number	Article Number	E-Number	Height (H)	Width (W)	Thickness (T)	Angle (a)
SLK15L1AB	196500		55 mm	19 mm	12.5 mm	90 ° Max
SLK15L2AB	196501	1319638	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L3AB	196502		55 mm	19 mm	12.5 mm	90 ° Max
SLK15L5AB	196503		55 mm	19 mm	12.5 mm	90 ° Max
SLK2L2AB	196529		55 mm	19 mm	12.5 mm	90 ° Max
SLK2L3AB	196530		55 mm	19 mm	12.5 mm	90 ° Max
SLK2L5AB	196531		55 mm	19 mm	12.5 mm	90 ° Max

CatalogNumber	Article Number	E-Number	Height (H)	Width (W)	Thickness (T)	Angle (a)
SLK3L10AB	196716		62 mm	24 mm	16 mm	90 ° Max
SLK3L2AB	196713		62 mm	24 mm	16 mm	90 ° Max
SLK3L5AB	196715		62 mm	24 mm	16 mm	90 ° Max

Table 3/3

Catalog Number	Article Number	E-Number	Static Load	Certifications
SLK15L1AB	196500		195N	ITB, UL, cUL
SLK15L2AB	196501	1319638	195N	ITB, UL, cUL
SLK15L3AB	196502		195N	cUL, ITB, UL
SLK15L5AB	196503		195N	ITB, UL, cUL
SLK2L2AB	196529		440N	ITB, UL, cUL
SLK2L3AB	196530		440N	ITB, UL, cUL
SLK2L5AB	196531		440N	ITB, UL, cUL
SLK3L10AB	196716		890N	
SLK3L2AB	196713		890N	
SLK3L5AB	196715		890N	

DIAGRAMS

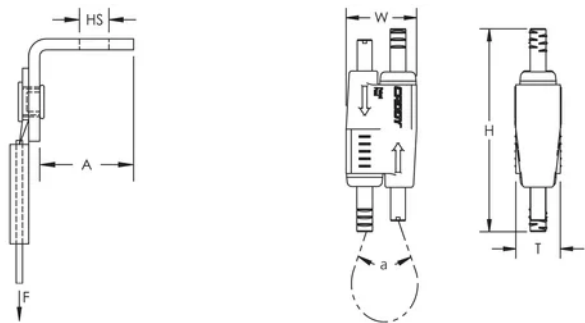

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

