

nVent CADDY Speed Link SLK with Decking Hook



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled decking hook end fitting

Quickly and easily attaches to hollow metal decking

Spring-loaded ends snap into decking hole and lock into place

Innovative design helps protect the wire from sharp edges of decking hole, minimizing risk of damage to wire

SPECIFICATIONS

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Zinc Alloy;Polypropylene
Complies With:	SMACNA HVAC-DCS

Table 1/2

Catalog Number	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	Roof Decking Sheet Thickness	A
----------------	----------------	----------	--------------------	------------------	------------------------------	---

SLK15L2DH	196677		1.5 mm	2m	1.5 mm Max	9.2 mm
SLK2L3DH	196532	1319648	2 mm	3m	1.5 mm Max	9.2 mm
SLK2L7DH	196534		2 mm	7m	1.5 mm Max	9.2 mm
SLK15L5DH	196505	1319640	1.5 mm	5m	1.5 mm Max	9.2 mm
SLK15L3DH	196504	1319639	1.5 mm	3m	1.5 mm Max	9.2 mm
SLK2L5DH	196533	1319649	2 mm	5m	1.5 mm Max	9.2 mm
SLK15L1DH	196676		1.5 mm	1m	1.5 mm Max	9.2 mm

Table 2/2				
Catalog Number	Article Number	E-Number	Hole Size (HS)	Static Load
SLK15L2DH	196677		8 mm	195N
SLK2L3DH	196532	1319648	8 mm	440N
SLK2L7DH	196534		8 mm	440N
SLK15L5DH	196505	1319640	8 mm	195N
SLK15L3DH	196504	1319639	8 mm	195N
SLK2L5DH	196533	1319649	8 mm	440N
SLK15L1DH	196676		8 mm	195N

Thickness (T): 12.5 mm

Width (W): 19 mm

Height (H): 55 mm


Angle (a): 90 ° Max

ADDITIONAL PRODUCT DETAILS

Load rating is only applicable if the load-bearing capacity of the supporting element (steel decking) is adequate.

Check with deck manufacturer for recommended load capacity.

DIAGRAMS

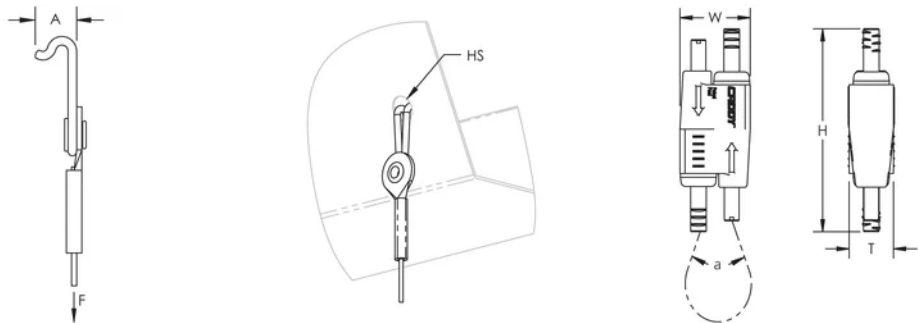

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

