

nVent CADDY Speed Link SLK with Toggle



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled toggle end fitting

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Also available in Y-toggle configuration

SPECIFICATIONS

Wire Rope Diameter:	1.5 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Zinc Alloy;Polypropylene
Complies With:	SMACNA HVAC-DCS

Table 1/1

Catalog Number	Article Number	E-Number	Wire Rope Length	A	B	Static Load
SLK15L10T	196526	1342892	10m	39 mm	5 mm	195N

CatalogNumber	Article Number	E-Number	Wire Rope Length	A	B	Static Load
SLK15L1T	196521	1342887	1m	39 mm	5 mm	195N
SLK15L2T	196522	1305139	2m	39 mm	5 mm	195N
SLK15L2TR2	196644		2m	39 mm	5 mm	195N
SLK15L3T	196523	1342889	3m	39 mm	5 mm	195N
SLK15L5T	196524	1342890	5m	39 mm	5 mm	195N
SLK15L7T	196525	1342891	7m	39 mm	5 mm	195N


Thickness (T): 12.5 mm

Width (W): 19 mm

Height (H): 55 mm

Angle (a): 90 ° Max

DIAGRAMS

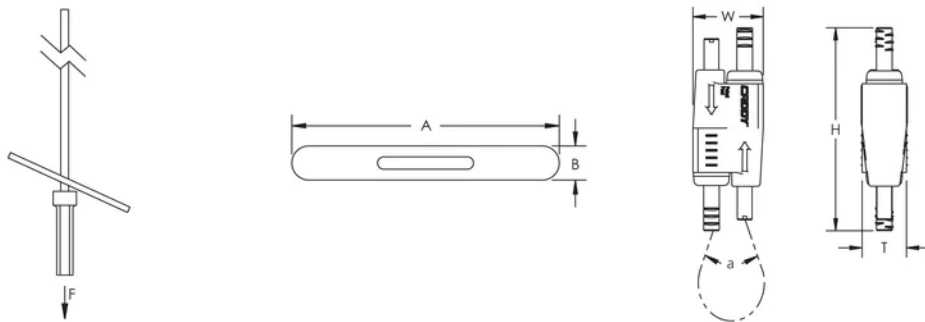

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

