

nVent CADDY Speed Link SLK with Wedge Anchor



FEATURES

Complete system includes wire, locking device and wedge anchor from fischerwerke GmbH &Co. KG

Quickly and easily attaches into cracked and non-cracked concrete

No special tools required

ETA 06/0175 approval available from fischerwerke GmbH &Co. KG

SPECIFICATIONS

Static Load Safety Factor:	5:1
Drill Bit Diameter:	6mm
Drill Hole Depth:	31mm
Embedment Depth:	25 mm Min
Finish:	Electrogalvanized
Material:	Steel;Polypropylene;Zinc Alloy

Table 1/2


Catalog Number	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	Length (L)	Height (H)
SLK15L3WA6	196672		1.5 mm	3m	54mm	55 mm
SLK2L3WA6	196735	3435585	2 mm	3m	54mm	55 mm

CatalogNumber	Article Number	E-Number	Wire Rope Diameter	Wire Rope Length	Length (L)	Height (H)
SLK15L2WA6	196671		1.5 mm	2m	54mm	55 mm
SLK2L2WA6	196734	1319678	2 mm	2m	54mm	55 mm

Table 2/2

Catalog Number	Article Number	E-Number	Width (W)	Thickness (T)	Angle (a)	Static Load
SLK15L3WA6	196672		19 mm	12.5 mm	90 ° Max	195N
SLK2L3WA6	196735	3435585	19 mm	12.5 mm	90 ° Max	300N
SLK15L2WA6	196671		19 mm	12.5 mm	90 ° Max	195N
SLK2L2WA6	196734	1319678	19 mm	12.5 mm	90 ° Max	300N

DIAGRAMS

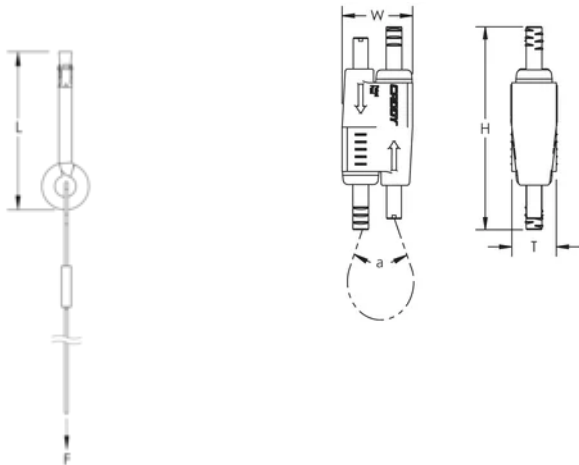

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

