


nVent CADDY Speed Link SLS with Decking Hook



CERTIFICATIONS

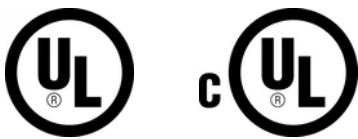

FEATURES

Complete system includes wire, locking device and pre-assembled decking hook end fitting

Quickly and easily attaches to hollow metal decking

Spring-loaded ends snap into decking hole and lock into place

Innovative design helps protect the wire from sharp edges of decking hole, minimizing risk of damage to wire

Finger tightening of nut secures the locking device into position without tools

Installs in strut profiles without the need to insert fingers or tools into the strut

SPECIFICATIONS

Wire Rope Diameter:	2 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Zinc Alloy;Polypropylene
Complies With:	SMACNA HVAC-DCS

Table 1/2

Catalog Number	Article Number	E-Number	Wire Rope Length	Roof Decking Sheet Thickness	A	Hole Size 1 (HS1)
SLS2L3DH	196753	3435604	3m	1.5 mm Max	9.2 mm	8 mm
SLS2L5DH	196754	3435605	5m	1.5 mm Max	9.2 mm	8 mm

Table 2/2

Catalog Number	Article Number	E-Number	Static Load
SLS2L3DH	196753	3435604	270N
SLS2L5DH	196754	3435605	270N

Slot Size (SS): 8 x 6.5 mm - 8 x 10 mm

Hole Size 2 (HS2): 8 - 10 mm

Width (W): 16 mm

Height 2 (H2): 46.5mm

Height 1 (H1): 53mm

Thread Size (TS): M8

Thickness (T): 4 mm Max

ADDITIONAL PRODUCT DETAILS


The 2 mm locking device is compatible with C-Channel Types E0 and E0L.

Total load per wire on a multi-tier trapeze must not exceed static load.

Load rating is only applicable if the load-bearing capacity of the supporting element (steel decking) is adequate.

Check with deck manufacturer for recommended load capacity.

DIAGRAMS

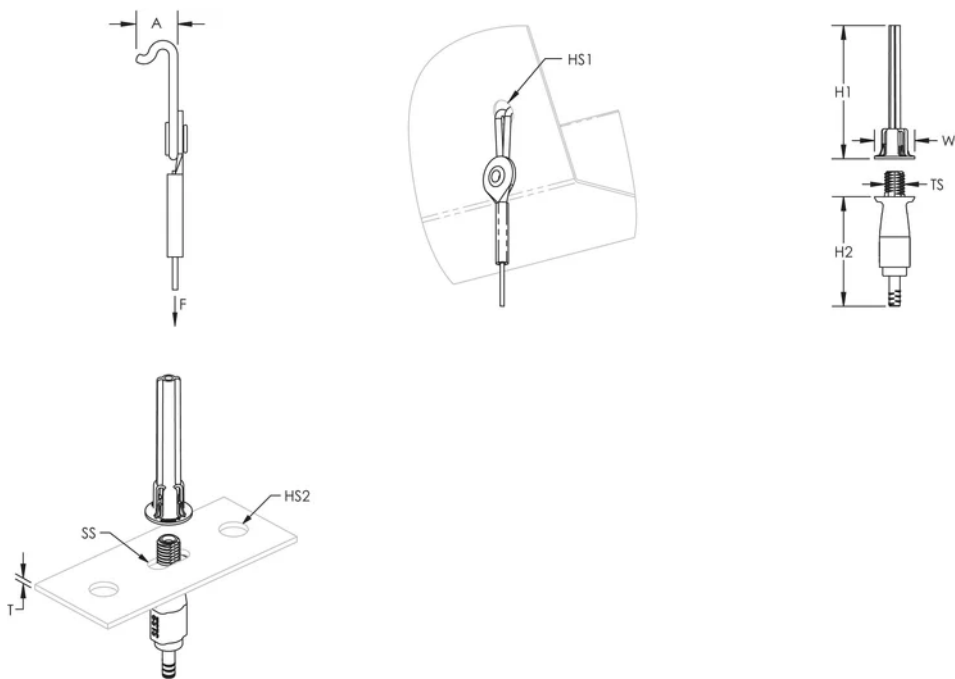

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

