

nVent CADDY Superfix 243 M8



CERTIFICATIONS



FEATURES

Includes easy closing mechanism

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

Temperature: -50 to 110 °C

Color: Black

Finish: Electrogalvanized

Material: Steel;EPDM-SBR Rubber

Table 1/2

Catalog Number	Article Number	E-Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
SXE061	589320	3435949	60 - 64 mm	50	M8	20 mm

CatalogNumber	Article Number	E-Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
SXE052	400062	3435842	48 - 53 mm	40	M8	20 mm
SXE028	400058	3435837	26 - 30 mm	20	M8	20 mm
SXE023	400057	3435836	20 - 23 mm	15	M8	20 mm
SXE043	400060	3435839	40 - 43 mm	32	M8	20 mm
SXE058	589310	3435948	50 - 55 mm		M8	20 mm
SXE014	400055	3435834	12 - 16 mm	8	M8	20 mm
SXE019	400056	3435835	15 - 19 mm	10	M8	20 mm
SXE035	400059	3435838	31 - 36 mm	25	M8	20 mm


Table 2/2						
Catalog Number	Article Number	E-Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
SXE061	589320	3435949	1.2 mm	5	30mm	1300N
SXE052	400062	3435842	1.2 mm	5	30mm	1300N
SXE028	400058	3435837	1.2 mm	5	25mm	1000N
SXE023	400057	3435836	1.2 mm	5	25mm	1000N
SXE043	400060	3435839	1.2 mm	5	30mm	1000N
SXE058	589310	3435948	1.2 mm	5	30mm	1300N
SXE014	400055	3435834	1.2 mm	5	25mm	1000N
SXE019	400056	3435835	1.2 mm	5	25mm	1000N

CatalogNumber	Article Number	E-Number	Thickness (T)	ScrewDiameter (Sc)	Screw Length (L)	Static Load
SXE035	400059	3435838	1.2 mm	5	30mm	1000N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

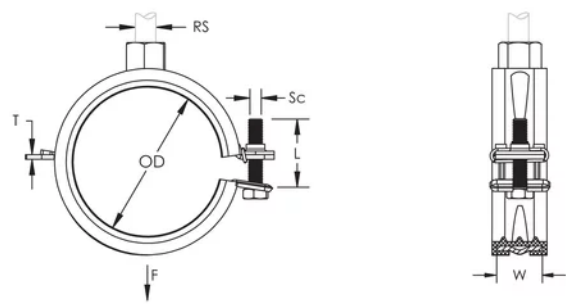

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

