

nVent CADDY Superfix 243 M8/M10



CERTIFICATIONS



FEATURES

Includes easy closing mechanism

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

Color:	Black
Finish:	Electrogalvanized
Material:	Steel;EPDM-SBR Rubber
Temperature:	-50 to 110 °C

Table 1/2

Catalog Number	Article Number	E-Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
SXD014	400063	3435843	12 - 16 mm	8	M8, M10	20 mm

CatalogNumber	Article Number	E-Number	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
SXD019	400064	3435844	15 - 19 mm	10	M8, M10	20 mm
SXD023	400065	3435845	20 - 23 mm	15	M8, M10	20 mm
SXD028	400066	3435846	26 - 30 mm	20	M8, M10	20 mm
SXD035	400067	3435847	31 - 36 mm	25	M8, M10	20 mm
SXD043	400068	3435848	40 - 43 mm	32	M8, M10	20 mm
SXD052	400070	3435851	48 - 53 mm	40	M8, M10	20 mm
SXD058	589350	3435951	50 - 55 mm		M8, M10	20 mm
SXD061	400071	3435852	60 - 64 mm	50	M8, M10	20 mm
SXD080	400074	3435855	74 - 80 mm	65	M8, M10	20 mm
SXD091	400075	3435856	87 - 92 mm	80	M8, M10	20 mm
SXD114	400077	3435858	108 - 114 mm	100	M8, M10	23 mm


Table 2/2						
Catalog Number	Article Number	E-Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
SXD014	400063	3435843	1.2 mm	5	25mm	1000N
SXD019	400064	3435844	1.2 mm	5	25mm	1000N
SXD023	400065	3435845	1.2 mm	5	25mm	1000N
SXD028	400066	3435846	1.2 mm	5	25mm	1000N
SXD035	400067	3435847	1.2 mm	5	25mm	1000N

CatalogNumber	Article Number	E-Number	Thickness (T)	ScrewDiameter (Sc)	Screw Length (L)	Static Load
SXD043	400068	3435848	1.2 mm	5	25mm	1000N
SXD052	400070	3435851	1.2 mm	5	25mm	1300N
SXD058	589350	3435951	1.2 mm	5	30mm	1300N
SXD061	400071	3435852	1.2 mm	5	30mm	1300N
SXD080	400074	3435855	2 mm	6	35mm	1300N
SXD091	400075	3435856	2 mm	6	35mm	1300N
SXD114	400077	3435858	2 mm	6	35mm	2200N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

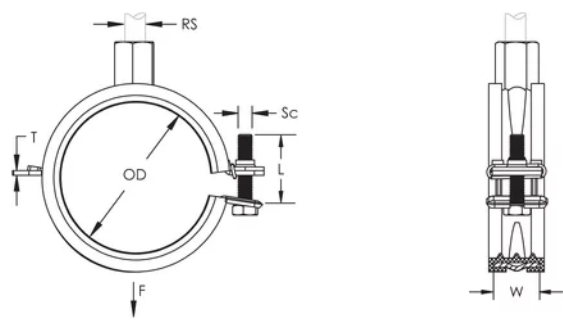

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

