

nVent CADDY Superklip



FEATURES

Closes and locks automatically when the pipe, tube or cable is inserted

One-piece clamp for fast and convenient installation

Fasten with either wood screw, dual threaded screw with or without collar, nail with collar, threaded rod, mounting plate or shot-fire bracket

SPECIFICATIONS

Material: Xenoy®

Temperature: -25 to 90 °C

Table 1/2


| Catalog Number | Article Number | E-Number | Outer Diameter (OD) | Copper Tube Size | B | C |
|----------------|----------------|----------|---------------------|------------------|---------|---------|
| 389017 | 389017 | 3435791 | 7.8 - 9.5 mm | 1/4" | 17.1 mm | 26.4 mm |
| 389018 | 389018 | 3435792 | 9.5 - 11.8 mm | 1/4" | 17.1 mm | 26.4 mm |
| 389003 | 389003 | 3535687 | 16.8 - 19.5 mm | 5/8" | 20 mm | 35.4 mm |
| 389001 | 389001 | 3535685 | 11.8 - 14.3 mm | 3/8" | 17.2 mm | 29.9 mm |
| 389004 | 389004 | 3535688 | 19.5 - 21.8 mm | | 20 mm | 39.4 mm |

| CatalogNumber | Article Number | E-Number | Outer Diameter (OD) | Copper Tube Size | B | C |
|---------------|----------------|----------|---------------------|------------------|---------|---------|
| 389002 | 389002 | 3535686 | 14.3 - 16.8 mm | 1/2" | 19.5 mm | 32 mm |
| 389005 | 389005 | 3535689 | 21.8 - 24.8 mm | 3/4" | 20 mm | 42 mm |
| 389006 | 389006 | 3535691 | 24.8 - 27.8 mm | | 20.2 mm | 45.1 mm |
| 389007 | 389007 | 3535692 | 27.8 - 31.2 mm | 1" | 20.2 mm | 48.9 mm |
| 389008 | 389008 | 3535693 | 31.2 - 35.5 mm | 1 1/4" | 21 mm | 54.4 mm |
| 389009 | 389009 | 3435785 | 35.5 - 39.5 mm | 1 1/4" | 21 mm | 59.4 mm |
| 389011 | 389011 | 3535694 | 39.5 - 43.5 mm | 1 1/2" | 21 mm | 64.2 mm |
| 389013 | 389013 | 3435787 | 50.5 - 55.5 mm | 2" | 23 mm | 78.7 mm |

| Table 2/2 | | | |
|----------------|----------------|----------|-------------|
| Catalog Number | Article Number | E-Number | Static Load |
| 389017 | 389017 | 3435791 | 135N |
| 389018 | 389018 | 3435792 | 150N |
| 389003 | 389003 | 3535687 | 190N |
| 389001 | 389001 | 3535685 | 160N |
| 389004 | 389004 | 3535688 | 200N |
| 389002 | 389002 | 3535686 | 175N |
| 389005 | 389005 | 3535689 | 215N |
| 389006 | 389006 | 3535691 | 240N |
| 389007 | 389007 | 3535692 | 260N |

| Catalog Number | Article Number | E-Number | Static Load |
|----------------|----------------|----------|-------------|
| 389008 | 389008 | 3535693 | 300N |
| 389009 | 389009 | 3435785 | 320N |
| 389011 | 389011 | 3535694 | 360N |
| 389013 | 389013 | 3435787 | 400N |

DIAGRAMS

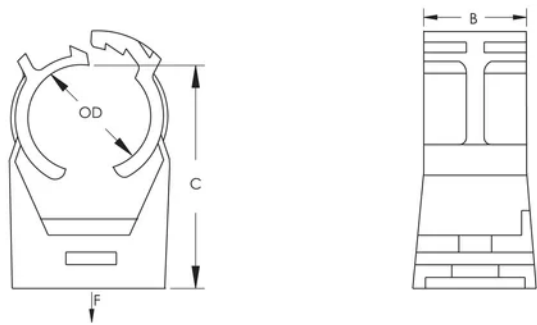

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

