

Oval Pipe Clamp with Nut



FEATURES

Designed to support pre-insulated twin tubes and integrated power cable for solar heat collectors

Shape of clamp provides a stable attachment to wall or ceiling

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel


Table 1/2

Catalog Number	Article Number	E-Number	NB/DN	Rod Size (RS)	A	B
MXOVDN25EG	403800		25	M8, M10	71 mm	124 mm
MXOVDN1618EG	401245	3535862	16, 18	M8, M10	51 mm	88 mm
MXOVDN1012EG	401161		10, 12	M8, M10	30 mm	69 mm
MXOVDN20EG	401246	3535863	20	M8, M10	58 mm	108 mm
MXOVDN1215EG	401244	3535861	12, 15	M8, M10	43 mm	78 mm

Table 2/2

Catalog Number	Article Number	E-Number	Width (W)	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)
MXOVDN25EG	403800		20 mm	2 mm	6	20mm
MXOVDN1618EG	401245	3535862	20 mm	2 mm	6	20mm
MXOVDN1012EG	401161		20 mm	2 mm	6	20mm
MXOVDN20EG	401246	3535863	20 mm	2 mm	6	20mm
MXOVDN1215EG	401244	3535861	20 mm	2 mm	6	20mm

DIAGRAMS

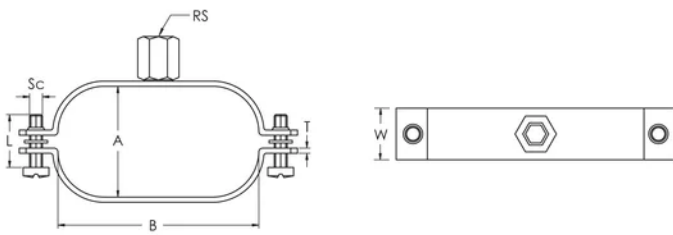

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

