

Pipe/Cable Clamp



FEATURES

Captive threaded stud minimizes the need for additional hardware

With the UNICBAND Sign Support Bracket and Fixoband Strap, attachments to pipe and pole can be made

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	NB/DN	Outer Diameter (OD)
CR037HD	336300	1342832	Steel	Hot-Dip Galvanized	10	16 - 20 mm
CR037S4	336400		Stainless Steel 304 (EN 1.4301)		10	16 - 20 mm
CR050HD	336310	1342833	Steel	Hot-Dip Galvanized	15	20 - 25 mm
CR050S4	336410	1319785	Stainless Steel 304 (EN 1.4301)		15	20 - 25 mm
CR075HD	336320	1342834	Steel	Hot-Dip Galvanized	20	26.9 - 31.8 mm
CR075S4	336420	1319786	Stainless Steel 304 (EN 1.4301)		20	26.9 - 31.8 mm


CatalogNumber	Article Number	E-Number	Material	Finish	NB/DN	Outer Diameter (OD)
CR087HD	336322		Steel	Hot-Dip Galvanized		32 - 34 mm
CR100HD	336330	1342835	Steel	Hot-Dip Galvanized	25	33.7 - 38 mm
CR100S4	336430	1319787	Stainless Steel 304 (EN 1.4301)		25	33.7 - 38 mm
CR125HD	336340	1342836	Steel	Hot-Dip Galvanized	32	40.0 - 44.5 mm
CR125S4	336440	1319788	Stainless Steel 304 (EN 1.4301)		32	40.0 - 44.5 mm
CR150HD	336350	1342837	Steel	Hot-Dip Galvanized	40	47 - 51 mm
CR150S4	336450	1319789	Stainless Steel 304 (EN 1.4301)		40	47 - 51 mm
CR200HD	336360	1342838	Steel	Hot-Dip Galvanized	50	59.2 - 63.5 mm
CR200S4	336460	1319790	Stainless Steel 304 (EN 1.4301)		50	59.2 - 63.5 mm

Table 2/2

Catalog Number	Article Number	E-Number	Width (W)	Static Load 1 (F1)	Static Load 2 (F2)
CR037HD	336300	1342832	16 mm	125N	550N
CR037S4	336400		16 mm	125N	550N
CR050HD	336310	1342833	16 mm	125N	550N
CR050S4	336410	1319785	16 mm	125N	550N
CR075HD	336320	1342834	16 mm	125N	550N
CR075S4	336420	1319786	16 mm	125N	550N
CR087HD	336322		16 mm	125N	550N

Catalog Number	Article Number	E-Number	Width (W)	Static Load 1 (F1)	Static Load 2 (F2)
CR100HD	336330	1342835	20 mm	250N	550N
CR100S4	336430	1319787	20 mm	250N	550N
CR125HD	336340	1342836	20 mm	250N	550N
CR125S4	336440	1319788	20 mm	250N	550N
CR150HD	336350	1342837	20 mm	250N	550N
CR150S4	336450	1319789	20 mm	250N	550N
CR200HD	336360	1342838	20 mm	250N	550N
CR200S4	336460	1319790	20 mm	250N	550N

DIAGRAMS

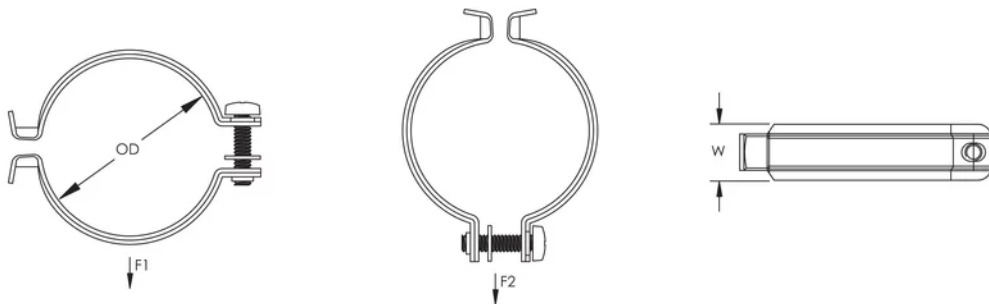

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

